


Joint Bond T6 Complete Welder Pair, Signal

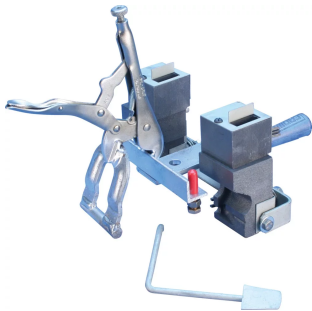

FEATURES

Complete welder assembly provides a convenient means of attaching jumper bonds to the head of the rail, across the joint

Connection is made within the confines of the splice bar

Includes mold cleaner

SPECIFICATIONS

Rail Type: 85 lb to 141 lb T-Rail Sections

Table 1/2

Catalog Number	Article Number	Material	Bond Terminal Style	Conductor Size	Conductor Outer Diameter, Nominal	Bond Length
SBHFT6A		Steel, Graphite, Thermoplastic	Head Free	3/16" Bondstrand	4.76mm	165.1mm
SBHFT6C		Steel, Graphite, Thermoplastic	Head Free	3/16" Bondstrand	4.76mm	190.5mm
SBHFT6D		Steel, Graphite, Thermoplastic	Head Free	3/16" Bondstrand	4.76mm	247.7mm
SBTBT6A		Steel, Graphite, Thermoplastic	1" Tab	3/16" Bondstrand	4.76mm	165.1mm
SBTBT6C		Steel, Graphite, Thermoplastic	3/4" Tab	3/16" Bondstrand	4.76mm	190.5mm

CatalogNumber	Article Number	Material	Bond Terminal Style	Conductor Size	Conductor OuterDiameter, Nominal	Bond Length
SBTBT6D	715408	Steel, Graphite, Thermoplastic	1" Tab	3/16" Bondstrand	4.76mm	247.7mm
SBXST6A		Steel, Graphite, Thermoplastic	3/4" XS	3/16" Bondstrand	4.76mm	165.1mm
SBXST6C	165570	Steel, Graphite, Thermoplastic	3/4" XS	3/16" Bondstrand	4.76mm	190.5mm
SBXST6D		Steel, Graphite, Thermoplastic	3/4" XS	3/16" Bondstrand	4.76mm	247.7mm
SBST6X2	222628	Steel, Graphite, Thermoplastic	1" Tab	35 mm ² Ropelay	7.75mm	177.8mm
SBHFT6B		Steel, Graphite, Thermoplastic	Head Free	5/16" Bondstrand	7.95mm	177.8mm
SBTBT6B		Steel, Graphite, Thermoplastic	1" Tab	5/16" Bondstrand	0.79mm	177.8mm
SBTBT6E		Steel, Graphite, Thermoplastic	1" Tab	5/16" Bondstrand	0.79mm	247.7mm

Table 2/2

Catalog Number	Article Number	Welder Style
SBHFT6A		T6
SBHFT6C		T6
SBHFT6D		T6
SBTBT6A		T6
SBTBT6C		T6
SBTBT6D	715408	T6
SBXST6A		T6
SBXST6C	165570	T6

Catalog Number	Article Number	Welder Style
SBXST6D		T6
SBST6X2	222628	T6
SBHFT6B		T6
SBTBT6B		T6
SBTBT6E		T6

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

⚠ WARNING: This product can expose you to chemicals including diisononyl phthalate, which is known to the State of California to cause cancer. For more information go to www.P65Warnings.ca.gov.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE