


Joint Bond T6 Mold Welder Frame Assembly, Signal

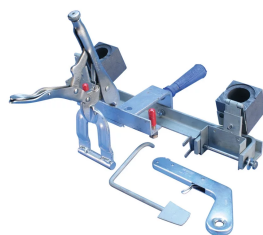

FEATURES

Replacement welder frame assembly for T6 joint bond welders

Includes frame with mold lid, mold handle, mold cleaner and flint ignitor

SPECIFICATIONS

Rail Type: 85 lb to 141 lb T-Rail Sections

Table 1/1

Catalog Number	Article Number	Material	Bond Terminal Style	Conductor Size	Conductor Outer Diameter, Nominal	Welder Style
SBXST6AX		Graphite, Steel, Thermoplastic	XS	3/16" Bondstrand	4.76mm	T6
SBXST6CX		Graphite, Steel, Thermoplastic	XS	3/16" Bondstrand	4.76mm	T6
SBXT6CE	161120	Graphite, Steel, Thermoplastic	W	50 mm ² Ropelay	9.13mm	T6

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper

installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

⚠ WARNING: This product can expose you to chemicals including diisononyl phthalate, which is known to the State of California to cause cancer. For more information go to www.P65Warnings.ca.gov.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY	ERICO	HOFFMAN	ILSCO	SCHROFF	TRACHTE
-------	-------	---------	-------	---------	---------