


Universal Pedestal Clamp with Cable Management, MBNUPCJ240

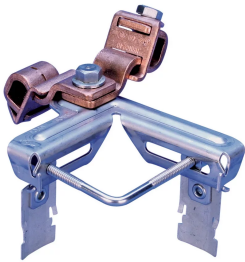

CERTIFICATIONS



FEATURES

Only one attachment required for both mesh bonding and cable management

Eliminates the need for separate mounting brackets for different pedestal types or sizes

Stainless steel construction of bracket and hardware reduces potential for galvanic corrosion

Mesh bonding conductors do not have to bend around each pedestal to conform to grid pattern


Suitable for round or square pedestals

SPECIFICATIONS

Table 1/1

Catalog Number	Material	Finish	Conductor Size	Pedestal Size
MBNUPCJ240	Copper, Сталь, Stainless Сталь 304 (EN 1.4301)	nVent CADDY Armour, Electrogalvanized	#2 Solid - 4/0 Stranded, 35 mm ² - 100 mm ²	22 - 51 mm Round or Square

DIAGRAMS

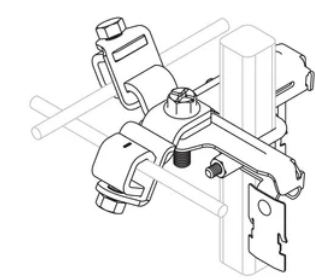

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE