


Drain-Breather, DPE

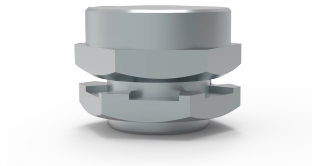

This stainless steel 316L element combine drainage and breathing and it is especially for use in potentially explosive atmosphere 'EX e'.

FEATURES

Description: Combination of drainage and breathing elements especially for use in potentially explosive atmosphere 'EX e'.

Protection degree: IP 66.

Temperature range: -30°C to 100°C.

Pack quantity: 1 piece.

SPECIFICATIONS

Table 1/1					
Catalog Number	Enclosure Material	Product Family	Material	Finish	Quick Ship
DPE3004S3	Mild Steel, Нержавеющая сталь	Free-Standing, Wall Mounted	Stainless Steel 316L	Brushed	No

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE