


, WO60

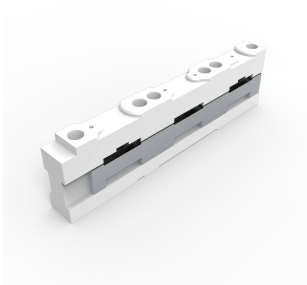

Busbar support that enables creation of a safe and easy to use system with 60 mm distance between busbar systems.

INDUSTRY STANDARDS

GL

DNV-GL

FEATURES

Description: Universal busbar support 3/4-Pole with internal screw holes, delivered without end cover.

Rated voltage: 690 V

Rated frequency: 50/60 Hz

Rated isolation voltage U_i : 1000 V

Rated surge voltage U_{imp} : 8 kV

Approvals: GL, DNV GL

Rated frequency: 50/60 Hz

Rated isolation voltage U_i : 1000 V

Rated surge voltage U_{imp} : 8 kV

SPECIFICATIONS

Table 1/1						
Catalog Number	Высота мм	Ширина мм	Глубина мм	Enclosure Material	Product Family	Material
01485	20mm	242mm	51mm	Plastic, Сталь	IEC General Accessories	Plastic, Сталь
01495	20mm	191mm	50mm	Plastic, Сталь	IEC General Accessories	Plastic, Сталь

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE