


, WO60

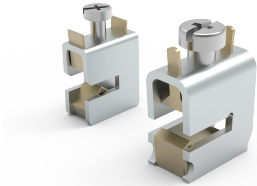

Terminlas for connecting round conductors on to flat busbars 1,5 mm² to 120 mm².

INDUSTRY STANDARDS

UL

CSA

GL

DNV-GL

FEATURES

Description: Universal conductor terminal with integrated holding spring, a captive clamping screw, and open terminal space.

Rated voltage: 690 V

Approvals: CSA, UL, GL, DNV-GL

Indication of nominal cross-section and tightening torque is noted on the terminal

Can be used with cover cap 01590

Universal conductor terminal with integrated holding spring, a captive clamping screw, and open terminal space

Rated voltage: 690 V

SPECIFICATIONS

Material: Mild Steel
Finish: Plated

Table 1/1						
Catalog Number	Высота мм	Ширина мм	Глубина мм	Connection Type	Max Current	Package Quantity
01068	15mm	17mm	21mm	16 - 120 mm²	440A	25
01284	7.5mm	7.5mm	21mm	1.5 - 16 mm²	180A	100
01285	11mm	10.5mm	21mm	4 - 35 mm²	270A	50
01287	14mm	14mm	21mm	16 - 70 mm²	400A	25
01289	7.5mm	7.5mm	21mm	1.5 - 16 mm²	180A	100
01203	15mm	17mm	21mm	16 - 120 mm²	440A	25
01290	11mm	10.5mm	21mm	4 - 35 mm²	270A	50
01292	14mm	14mm	21mm	16 - 70 mm²	400A	25

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE