 


# PFF Parallel Plastic Screw-In Plug for P13/P14 Couplers, Worldwide Design



## FEATURES

Designed for use with the P13/P14 coupler families

Designed to keep dirt, water and concrete slurry out of the coupler during the concrete pour

Durable mounting plates allow for easy attachment to forms

Color coded for the appropriate coupler size

## SPECIFICATIONS

**Design Version:** Worldwide (Globally Available Materials)

Table 1/2


| Catalog Number | Material                                | Rebar Size, Metric | Rebar Size, US | Rebar Size, Canada | Diameter (Ø) | Height (H) |
|----------------|-----------------------------------------|--------------------|----------------|--------------------|--------------|------------|
| EL12PFFN       | High Density Polyethylene (HDPE), Сталь | 12 mm              | #4             | 10M                | 65 mm        | 17 mm      |
| EL28PFFN       | High Density Polyethylene (HDPE), Сталь | 28 mm              | #9             | 30M                | 95 mm        | 20 mm      |
| EL40PFFN       | High Density Polyethylene (HDPE), Сталь | 40 mm              |                |                    | 95 mm        | 20 mm      |

| CatalogNumber | Material                                | Rebar Size, Metric | Rebar Size, US | Rebar Size, Canada | Diameter (Ø) | Height (H) |
|---------------|-----------------------------------------|--------------------|----------------|--------------------|--------------|------------|
| EL20PFFN      | High Density Polyethylene (HDPE), Сталь | 20 mm              | #6             | 20M                | 75 mm        | 20 mm      |
| EL36PFFN      | High Density Polyethylene (HDPE), Сталь | 36 mm              | #11            | 35M                | 95 mm        | 20 mm      |
| EL22PFFN      | High Density Polyethylene (HDPE), Сталь | 22 mm              | #7             |                    | 95 mm        | 20 mm      |
| EL16PFFN      | High Density Polyethylene (HDPE), Сталь | 16 mm              | #5             | 15M                | 65 mm        | 20 mm      |
| EL32PFFN      | High Density Polyethylene (HDPE), Сталь | 32 mm              | #10            |                    | 95 mm        | 20 mm      |
| EL25PFFN      | High Density Polyethylene (HDPE), Сталь | 25 mm              | #8             | 25M                | 95 mm        | 20 mm      |

Table 2/2

| Catalog Number | Color   |
|----------------|---------|
| EL12PFFN       | Красный |
| EL28PFFN       | Черный  |
| EL40PFFN       | Зеленый |
| EL20PFFN       | Yellow  |
| EL36PFFN       | Blue    |
| EL22PFFN       | Blue    |
| EL16PFFN       | Черный  |
| EL32PFFN       | Yellow  |
| EL25PFFN       | Красный |

DIAGRAMS

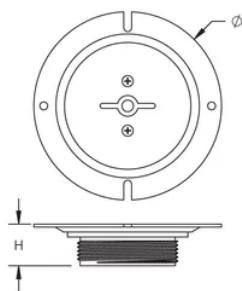

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical  
Support

Europe

Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

Europe

Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

APAC

Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE