


Front Panel, Refrofit Shielding, 6 U, 6 HP

Power Utilities

CATALOG NUMBER

20846-445

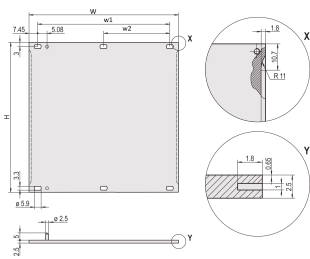

Flat front panel. Shieldable with stainless steel EMC gasket.

CERTIFICATIONS



FEATURES

For stainless steel EMC gasket

Aluminum, 2.5 mm, front anodized, conductive

PRODUCT ATTRIBUTES

Product Type: Передняя панель

Type: Front Panel without Handle

Mounting: Screw-on Front

EMC Shielding: No (Retrofittable)

Gasket Type: Нержавеющая сталь

Material: Алюминий

Front Finish: Anodized

Rear Finish: Conductive

Treated Edges: Нет

Rack Height: 6 U

Высота мм: 261.8 mm

Rack Width: 6 HP

Ширина мм: 30.1 mm

Complies With: IEC 60297-3-101; IEEE 1101.1/10

Package Quantity: 5

ADDITIONAL PRODUCT DETAILS

Please order fixing material (sleeves, collar screws) separately.

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE