


Front Panel, Shielded, Bottom Hinged

Power Utilities

U-profile front panel bottom hinged for textile gasket.

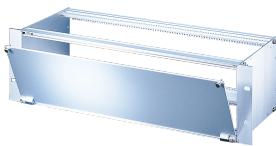

CERTIFICATIONS



FEATURES

U-profile front panel can be unhinged at 135° (not RatiopacPRO) opening angle

Enables mounting on horizontal rails

Shielded, U front panel with textile EMC gasket

Suitable for sub racks (EuropacPRO) and cases (RatiopacPRO, PropacPRO, CompacPRO)

SPECIFICATIONS

Table 1/3

Catalog Number	Rack Height	Rack Width	Package Quantity	Mounting	EMC Gasket Type	Front Finish
20848-599	3 U	42 HP	1	Hinged, Bottom	Textile	Anodized
20848-600	3 U	63 HP	1	Hinged, Bottom	Textile	Anodized

CatalogNumber	Rack Height	Rack Width	Package Quantity	Mounting	EMC Gasket Type	Front Finish
20848-601	3 U	84 HP	1	Hinged, Bottom	Textile	Anodized
20848-602	6 U	42 HP	1	Hinged, Bottom	Textile	Anodized
20848-603	6 U	63 HP	1	Hinged, Bottom	Textile	Anodized
20848-604	6 U	84 HP	1	Hinged, Bottom	Textile	Anodized
20848-605	4 U	42 HP	1	Hinged, Bottom	Textile	Anodized
20848-606	4 U	63 HP	1	Hinged, Bottom	Textile	Anodized
20848-607	4 U	84 HP	1	Hinged, Bottom	Textile	Anodized
20848-608	3 U	28 HP	1	Hinged, Bottom	Textile	Anodized
20848-696	6 U	28 HP	1	Hinged, Bottom	Textile	Anodized

Table 2/3						
Catalog Number	Rear Finish	Treated Edges	Complies With	EMC Shielding	Высота мм	Material
20848-599	Conductive	Нет	IEC 60297-3-101, IEEE 1101.1/10	No (Retrofittable)	128.4 mm	Алюминий
20848-600	Conductive	Нет	IEC 60297-3-101, IEEE 1101.1/10	No (Retrofittable)	128.4 mm	Алюминий
20848-601	Conductive	Нет	IEC 60297-3-101, IEEE 1101.1/10	No (Retrofittable)	128.4 mm	Алюминий
20848-602	Conductive	Нет	IEC 60297-3-101, IEEE 1101.1/10	No (Retrofittable)	261.8 mm	Алюминий
20848-603	Conductive	Нет	IEC 60297-3-101, IEEE 1101.1/10	No (Retrofittable)	261.8 mm	Алюминий
20848-604	Conductive	Нет	IEC 60297-3-101, IEEE 1101.1/10	No (Retrofittable)	261.8 mm	Алюминий

CatalogNumber	Rear Finish	Treated Edges	Complies With	EMC Shielding	Высота мм	Material
20848-605	Conductive	Нет	IEC 60297-3-101, IEEE 1101.1/10	No (Retrofittable)	172.9 mm	Алюминий
20848-606	Conductive	Нет	IEC 60297-3-101, IEEE 1101.1/10	No (Retrofittable)	172.9 mm	Алюминий
20848-607	Conductive	Нет	IEC 60297-3-101, IEEE 1101.1/10	No (Retrofittable)	172.9 mm	Алюминий
20848-608	Conductive	Нет	IEC 60297-3-101, IEEE 1101.1/10	No (Retrofittable)	128.4 mm	Алюминий
20848-696	Conductive	Нет	IEC 60297-3-101, IEEE 1101.1/10	No (Retrofittable)	261.8 mm	Алюминий

Table 3/3

Catalog Number	Product Type	Type	Ширина мм
20848-599	Передняя панель	Front Panel without Handle	213 mm
20848-600	Передняя панель	Front Panel without Handle	319.7 mm
20848-601	Передняя панель	Front Panel without Handle	426.4 mm
20848-602	Передняя панель	Front Panel without Handle	213 mm
20848-603	Передняя панель	Front Panel without Handle	319.7 mm
20848-604	Передняя панель	Front Panel without Handle	426.4 mm
20848-605	Передняя панель	Front Panel without Handle	213 mm
20848-606	Передняя панель	Front Panel without Handle	319.7 mm
20848-607	Передняя панель	Front Panel without Handle	426.4 mm
20848-608	Передняя панель	Front Panel without Handle	141.9 mm
20848-696	Передняя панель	Front Panel without Handle	141.9 mm

ADDITIONAL PRODUCT DETAILS

Front panel can be removed in opened position (> 135°).

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE