


Novastar Glass Door, 180° Opening Angle

Power Utilities

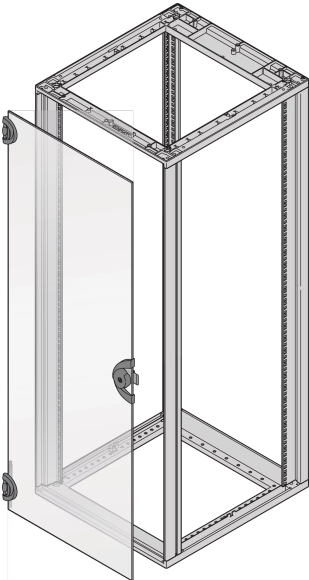

Glazed / Glass doors for aluminum frame cabinets with attractive design, ideally suited for general electronics, test & measurement, audio/video and broadcasting applications.

CERTIFICATIONS



FEATURES

Glass type: ESG 6 mm, EN 12150

Opening angle 180°

Lock with key

Can be assembled at front and rear

SPECIFICATIONS

Table 1/2

Catalog Number	Rack Height	Высота мм	Ширина мм	Color	Color Code	Product Type
27230-001	6 U	323 mm	553 mm	Light Grey	RAL 7035	Cabinet Door
27230-002	9 U	422 mm	553 mm	Light Grey	RAL 7035	Cabinet Door
27230-003	12 U	555 mm	553 mm	Light Grey	RAL 7035	Cabinet Door
27230-004	16 U	733 mm	553 mm	Light Grey	RAL 7035	Cabinet Door
27230-005	20 U	911 mm	553 mm	Light Grey	RAL 7035	Cabinet Door
27230-006	25 U	1133 mm	553 mm	Light Grey	RAL 7035	Cabinet Door
27230-028	29 U	1345 mm	553 mm	Light Grey	RAL 7035	Cabinet Door
27230-007	34 U	1534 mm	553 mm	Light Grey	RAL 7035	Cabinet Door
27230-008	38 U	1711 mm	553 mm	Light Grey	RAL 7035	Cabinet Door
27230-009	43 U	1933 mm	553 mm	Light Grey	RAL 7035	Cabinet Door
27230-010	47 U	2111 mm	553 mm	Light Grey	RAL 7035	Cabinet Door

Table 2/2

Catalog Number	Type
27230-001	Glass Door
27230-002	Glass Door
27230-003	Glass Door
27230-004	Glass Door
27230-005	Glass Door

Catalog Number	Type
27230-006	Glass Door
27230-028	Glass Door
27230-007	Glass Door
27230-008	Glass Door
27230-009	Glass Door
27230-010	Glass Door

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE