


Сборочная деталь

Крепежные винты с цилиндрической головкой.

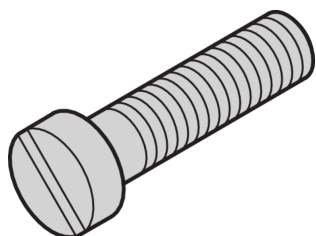

CERTIFICATIONS



FEATURES

Винт для крепления передней ручки, откидных опорных ножек, мезонинной платы PMC или ВЧ-кассеты

SPECIFICATIONS

Product Type: Screw

Type: Screw

Table 1/2

Catalog Number	Длина мм	Material	Finish	Package Quantity	Thread Size	Works With
21100-431	4mm	Сталь	Nickel Plated	100	M2.5	Передние панели
21100-624	5mm	Сталь		100	M2.5	Передние панели
21101-211	12mm	Сталь	Zinc Plated	100	M4	Передние панели

Table 2/2

Catalog Number	Quick Ship
----------------	------------

21100-431	No
21100-624	No
21101-211	No

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE