

# ATCA Front Panel Kit With Spring Loading



Передняя панель AdvancedTCA для ручки IEA с пружиной (плунжерного или нажимного типа) с литым наконечником из алюминиевого профиля или нержавеющей стали.

## CERTIFICATIONS



## FEATURES

Передняя панель (усиленная, с отлитым под давлением наконечником)

Ручка ATCA IEA с пружиной

Текстильный ЭМС-уплотнитель и крепежный материал

## SPECIFICATIONS

|                       |                 |
|-----------------------|-----------------|
| <b>Rack Width:</b>    | 6HP             |
| <b>Rack Height:</b>   | 8U              |
| <b>Аксессуар Тип:</b> | Передняя панель |
| <b>Product Type:</b>  | Передняя панель |

Table 1/2


| Catalog Number | Material | Finish     | Package Quantity | Front Finish | Rear Finish | Глубина мм (D) |
|----------------|----------|------------|------------------|--------------|-------------|----------------|
| 20818-170      | Алюминий | Passivated | 1                | Raw          | Raw         | 1mm            |
| 20818-169      | Алюминий | Passivated | 1                | Raw          | Raw         | 1mm            |

| CatalogNumber | Material          | Finish | Package Quantity | Front Finish | Rear Finish | Глубина мм(D) |
|---------------|-------------------|--------|------------------|--------------|-------------|---------------|
| 20818-161     | Нержавеющая сталь |        | 1                | Raw          | Raw         | 1mm           |
| 20818-160     | Нержавеющая сталь |        | 1                | Raw          | Raw         | 1mm           |

Table 2/2

| Catalog Number | Высота мм (H) | Ширина мм (W) | Quick Ship |
|----------------|---------------|---------------|------------|
| 20818-170      | 323.15mm      | 28.95mm       | No         |
| 20818-169      | 323.15mm      | 28.95mm       | No         |
| 20818-161      | 323.15mm      | 28.95mm       | No         |
| 20818-160      | 323.15mm      | 28.95mm       | No         |

## DIAGRAMS

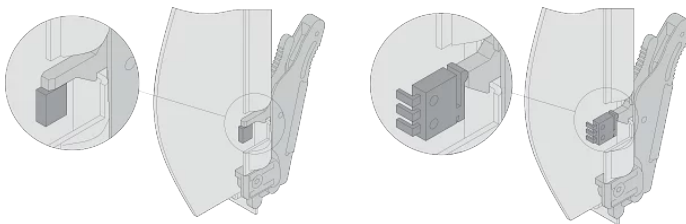

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)



Our powerful portfolio of brands:

**CADDY**

**ERICO**

**HOFFMAN**

**ILSCO**

**SCHROFF**

**TRACHTE**