


Силовая объединительная плата CPCI с разъемом P 47

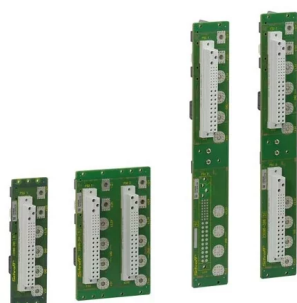

Силовая объединительная плата для режимов применения CompactPCI. С разъемом питания P47.

CERTIFICATIONS



FEATURES

В соответствии с: Спецификация интерфейса по питанию CompactPCI, PICMG 2.11 R1.0

В соответствии с: спецификация системной управляющей шины PICMG 2.9 R1.0

одинарный, параллельный или резервированный режим работы

Изменяемый географический адрес

Подача сетевого питания через фиксируемые в штекере обжимные контакты, питающее напряжение на объединительной плате отсутствует

Кабель питания заказывается отдельно в качестве принадлежности

Выходы постоянного тока с соединениями Powerbug для экстремально низкого падения напряжения

Выходы постоянного тока с соединениями Powerbug для экстремально низкого падения напряжения

SPECIFICATIONS

Table 1/2

Catalog Number	Product Type	Number of Slots	Rack Height	Backplane Type	Slot Width	Connector Type
----------------	--------------	-----------------	-------------	----------------	------------	----------------

23098-393	Объединительная плата	1	3U	CompactPCI Power Backplane with P47	8HP	
23098-396	Объединительная плата	1	6U	CompactPCI Power Backplane with P47	8HP	
23098-395	Объединительная плата	1	6U	CompactPCI Power Backplane with P47	8HP	
23098-394	Объединительная плата	2	3U	CompactPCI Power Backplane with P47	8HP	P47

Table 2/2

Catalog Number	Power Connector Type	Utility Connector Type	Ширина мм	Package Quantity	Quick Ship
23098-393	(1) P47	SMCQ, 12-pin, MicroMatch, 10-pin	39.6mm	1	No
23098-396	(2) P47	SMCQ, 12-pin, MicroMatch, 10-pin	39.6mm	1	No
23098-395	(1) P47	SMCQ, 12-pin, MicroMatch, 10-pin	39.6mm	1	No
23098-394	(2) P47	SMCQ, 12-pin, MicroMatch, 10-pin	80.3mm	1	No

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE