


Объединительная плата CPCI Serial

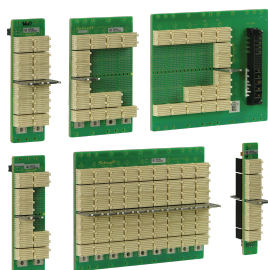

Объединительные платы nVent SCHROFF CompactPCI Serial поддерживают самые высокие скорости передачи данных с помощью PCIe до Gen 3, 10 GbE, USB 3.0 и S-ATA ред. 3,0

CERTIFICATIONS



FEATURES

Соответствует спецификации PICMG CompactPCI Serial (CPCI-S.0 R2.0)

Сервисный разъем для подключения к задней части объединительной платы

Механическая центрирующая кодирующая лента из нержавеющей стали на каждом укомплектованном переднем и заднем слотах

SPECIFICATIONS

Table 1/2

Catalog Number	Product Type	Number of Slots	Rack Height	Backplane Type	System Slot	Slot Width
23007-621	Объединительная плата	1	3U	CompactPCI Serial, No Bus		4HP
23007-641	Объединительная плата	1	3U	CompactPCI Serial, No Bus		4HP
23007-661	Объединительная плата	1	3U	CompactPCI Serial, No Bus		4HP
23007-681	Объединительная плата	1	3U	CompactPCI Serial, No Bus		4HP

CatalogNumber	Product Type	Number ofSlots	Rack Height	BackplaneType	System Slot	Slot Width
23007-605	Объединительная плата	5	3U	CompactPCI Serial with Ethernet Full-mesh	Right	4HP
23007-615	Объединительная плата	5	3U	CompactPCI Serial with Ethernet Full-mesh	Right	4HP
23007-627	Объединительная плата	7	3U	CompactPCI Serial with Ethernet Star	Left	4HP
23007-628	Объединительная плата	8	3U	CompactPCI Serial with Ethernet Star	Left	4HP
23007-629	Объединительная плата	9	3U	CompactPCI Serial with Ethernet Star	Left	4HP
23007-636	Объединительная плата	6	3U	CompactPCI Serial with Ethernet Star	Right	4HP
23007-637	Объединительная плата	7	3U	CompactPCI Serial with Ethernet Star	Right	4HP
23007-639	Объединительная плата	9	3U	CompactPCI Serial with Ethernet Star	Right	4HP
23007-642	Объединительная плата	2	3U	CompactPCI Serial with Ethernet Full-mesh	Left	4HP
23007-643	Объединительная плата	3	3U	CompactPCI Serial with Ethernet Full-mesh	Left	4HP
23007-644	Объединительная плата	4	3U	CompactPCI Serial with Ethernet Full-mesh	Left	4HP
23007-645	Объединительная плата	5	3U	CompactPCI Serial with Ethernet Full-mesh	Left	4HP
23007-649	Объединительная плата	9	3U	CompactPCI Serial with Ethernet Full-mesh	Left	4HP

CatalogNumber	Product Type	Number ofSlots	Rack Height	BackplaneType	System Slot	Slot Width
23007-653	Объединительная плата	3	3U	CompactPCI Serial with Ethernet Full-mesh	Right	4HP
23007-654	Объединительная плата	4	3U	CompactPCI Serial with Ethernet Full-mesh	Right	4HP
23007-655	Объединительная плата	5	3U	CompactPCI Serial with Ethernet Full-mesh	Right	4HP
23007-667	Объединительная плата	7	3U	CompactPCI Serial with Ethernet Star	Left	4HP
23007-668	Объединительная плата	8	3U	CompactPCI Serial with Ethernet Star	Left	4HP
23007-669	Объединительная плата	9	3U	CompactPCI Serial with Ethernet Star	Left	4HP
23007-676	Объединительная плата	6	3U	CompactPCI Serial with Ethernet Star	Right	4HP
23007-677	Объединительная плата	7	3U	CompactPCI Serial with Ethernet Star	Right	4HP
23007-679	Объединительная плата	9	3U	CompactPCI Serial with Ethernet Star	Right	4HP
23007-682	Объединительная плата	2	3U	CompactPCI Serial with Ethernet Full-mesh	Left	4HP
23007-683	Объединительная плата	3	3U	CompactPCI Serial with Ethernet Full-mesh	Left	4HP
23007-684	Объединительная плата	4	3U	CompactPCI Serial with Ethernet Full-mesh	Left	4HP
23007-685	Объединительная плата	5	3U	CompactPCI Serial with Ethernet Full-mesh	Left	4HP

CatalogNumber	Product Type	Number ofSlots	Rack Height	BackplaneType	System Slot	Slot Width
23007-689	Объединительная плата	9	3U	CompactPCI Serial with Ethernet Full-mesh	Left	4HP
23007-693	Объединительная плата	3	3U	CompactPCI Serial with Ethernet Full-mesh	Right	4HP
23007-694	Объединительная плата	4	3U	CompactPCI Serial with Ethernet Full-mesh	Right	4HP
23007-695	Объединительная плата	5	3U	CompactPCI Serial with Ethernet Full-mesh	Right	4HP

Table 2/2						
Catalog Number	Connector Type	Power Connector Type	Utility Connector Type	Ширина мм	Package Quantity	Quick Ship
23007-621	AirMax VS	Microfit	MicroMatch, 10-pin	19.3mm	1	No
23007-641	AirMax VS	Microfit	MicroMatch, 10-pin	19.3mm	1	No
23007-661	AirMax VS	Microfit	MicroMatch, 10-pin	19.3mm	1	No
23007-681	AirMax VS	Microfit	MicroMatch, 10-pin	19.3mm	1	No
23007-605	AirMax VS	PwrBlade	MicroMatch, 10-pin	159.9mm	1	No
23007-615	AirMax VS	PwrBlade	MicroMatch, 10-pin	159.9mm	1	No
23007-627	AirMax VS	Power Bugs for M4 Cable Lugs	MicroMatch, 10-pin	141.2mm	1	No
23007-628	AirMax VS	Power Bugs for M4 Cable Lugs	MicroMatch, 10-pin	161.6mm	1	No
23007-629	AirMax VS	Power Bugs for M4 Cable Lugs	MicroMatch, 10-pin	181.9mm	1	No
23007-636	AirMax VS	Power Bugs for M4 Cable Lugs	MicroMatch, 10-pin	120.9mm	1	No

CatalogNumber	ConnectorType	Power ConnectorType	Utility ConnectorType	Ширина мм	Package Quantity	Quick Ship
23007-637	AirMax VS	Power Bugs for M4 Cable Lugs	MicroMatch, 10-pin	141.2mm	1	No
23007-639	AirMax VS	Power Bugs for M4 Cable Lugs	MicroMatch, 10-pin	181.9mm	1	No
23007-642	AirMax VS	Power Bugs for M4 Cable Lugs	MicroMatch, 10-pin	19.3mm	1	No
23007-643	AirMax VS	Power Bugs for M4 Cable Lugs	MicroMatch, 10-pin	60mm	1	No
23007-644	AirMax VS	Power Bugs for M4 Cable Lugs	MicroMatch, 10-pin	80.3mm	1	No
23007-645	AirMax VS	Power Bugs for M4 Cable Lugs	MicroMatch, 10-pin	100.6mm	1	No
23007-649	AirMax VS	Power Bugs for M4 Cable Lugs	MicroMatch, 10-pin	191.9mm	1	No
23007-653	AirMax VS	Power Bugs for M4 Cable Lugs	MicroMatch, 10-pin	60mm	1	No
23007-654	AirMax VS	Power Bugs for M4 Cable Lugs	MicroMatch, 10-pin	80.3mm	1	No
23007-655	AirMax VS	Power Bugs for M4 Cable Lugs	MicroMatch, 10-pin	100.6mm	1	No
23007-667	AirMax VS	Power Bugs for M4 Cable Lugs	MicroMatch, 10-pin	141.2mm	1	No
23007-668	AirMax VS	Power Bugs for M4 Cable Lugs	MicroMatch, 10-pin	161.6mm	1	No
23007-669	AirMax VS	Power Bugs for M4 Cable Lugs	MicroMatch, 10-pin	181.9mm	1	No
23007-676	AirMax VS	Power Bugs for M4 Cable Lugs	MicroMatch, 10-pin	120.9mm	1	No
23007-677	AirMax VS	Power Bugs for M4 Cable Lugs	MicroMatch, 10-pin	141.2mm	1	No
23007-679	AirMax VS	Power Bugs for M4 Cable Lugs	MicroMatch, 10-pin	181.9mm	1	No
23007-682	AirMax VS	Power Bugs for M4 Cable Lugs	MicroMatch, 10-pin	39.6mm	1	No
23007-683	AirMax VS	Power Bugs for M4 Cable Lugs	MicroMatch, 10-pin	60mm	1	No

CatalogNumber	ConnectorType	Power ConnectorType	Utility ConnectorType	Ширина мм	Package Quantity	Quick Ship
23007-684	AirMax VS	Power Bugs for M4 Cable Lugs	MicroMatch, 10-pin	80.3mm	1	No
23007-685	AirMax VS	Power Bugs for M4 Cable Lugs	MicroMatch, 10-pin	100.6mm	1	No
23007-689	AirMax VS	Power Bugs for M4 Cable Lugs	MicroMatch, 10-pin	181.9mm	1	No
23007-693	AirMax VS	Power Bugs for M4 Cable Lugs	MicroMatch, 10-pin	60mm	1	No
23007-694	AirMax VS	Power Bugs for M4 Cable Lugs	MicroMatch, 10-pin	80.3mm	1	No
23007-695	AirMax VS	Power Bugs for M4 Cable Lugs	MicroMatch, 10-pin	100.6mm	1	No

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE