


Двойная тестовая розетка, Ø 2 мм

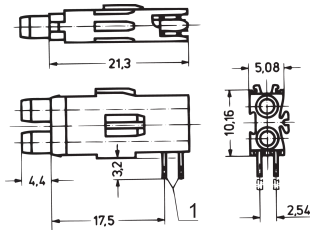

Двойные тестовые гнезда для монтажной поверхности 1 и 2, короткий и длинный тип.

Температуру припоя следует применять не более чем на 5 секунд. При пайке волной пластиковый корпус должен быть защищен от волны припоя.

CERTIFICATIONS



FEATURES

Двойные тестовые гнезда для системы передних элементов

Укороченная корнструктивная форма для монтажной плоскости 1

SPECIFICATIONS

Diameter: 2mm
Product Type: Socket

Table 1/2

Catalog Number	Type	Package Quantity	Voltage AC	Max Current	Test Voltage @ 50 Hz	Ambient Temperature
69004-089	Long, Mounting Plane 1	1	30V	1A	1kV	-25 to 70°C
69004-131	Short, Mounting Plane 1	1	30V	1A	1kV	-25 to 70°C
69004-090	Long, Mounting Plane 2	10	30V	1A	1kV	-25 to 70°C

Table 2/2

Catalog Number	Solder Temperature	Flammability Rating	Quick Ship
----------------	--------------------	---------------------	------------

69004-089	260°C	UL® 94V-0	No
69004-131	260°C	UL® 94V-0	No
69004-090	260°C	UL® 94V-0	No

ADDITIONAL PRODUCT DETAILS

Dimensions of connecting pins: 0,3 x 0,6 mm.

Обратите внимание, что поставки доступны в указанных стандартных товарных партиях (товарная партия, например, 5 шт., 10 шт., 50 шт. и т. д.). Другие объемы заказов (например, 2 шт.) могут округляться вверх до следующего возможного размера стандартной товарной партии.

Required front panel drill hole: Ø 4 mm.

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE