


19-дюймовый вентиляторный блок, высота 1 U, 3 вентиляторов, 230 В перем. тока

CATALOG NUMBER

10713-100

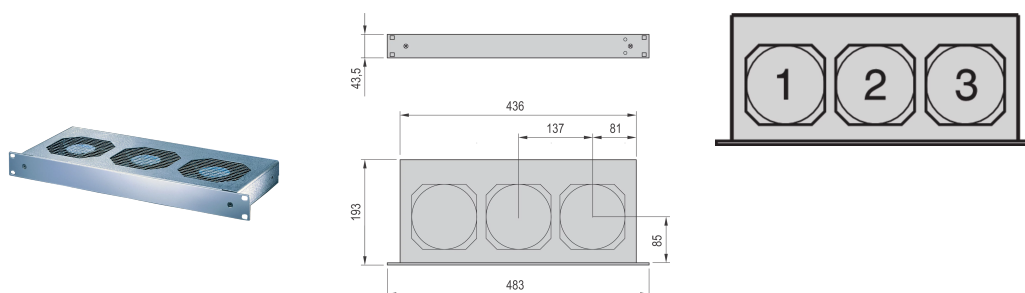

Вентиляторный блок для установки в пространство 1U внутри шкафа.

CERTIFICATIONS



FEATURES

Механическое уменьшение нагрузки для сетевых кабелей

Возможность использования в комбинации с блочным каркасом

Защита от прикосновения в соответствии с DIN EN ISO 13857

PRODUCT ATTRIBUTES

Product Type: Fan Unit

Input Voltage AC: 230V

Package Quantity: 1

Finish: Aluminum-Zinc Plated; Anodized

Material: Сталь; Алюминий

Net Weight: 3.29kg

ADDITIONAL PRODUCT DETAILS

Сетевой кабель заказывается отдельно.

Решения с широким диапазоном входного напряжения (86 ... 264 В перем. тока) доступны по запросу.

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE