
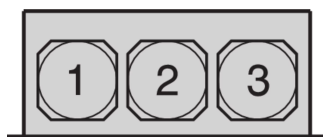


19-дюймовый вентиляторный блок, высота 1 U, с передним переключателем, 3 вентиляторов, 230 В перем. тока

CATALOG NUMBER

10713-108

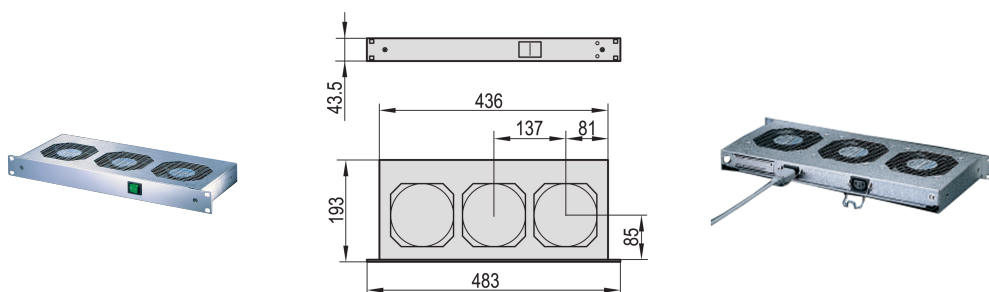

Сетевой выключатель с подсветкой на передней панели в исполнениях для переменного тока, соединенный с дополнительным сетевым выходом с тыльной стороны; уменьшение механической нагрузки на входной и выходной сетевой кабель.

CERTIFICATIONS



FEATURES

Возможность использования в комбинации с блочным каркасом

Защита от прикосновения в соответствии с DIN EN ISO 13857

PRODUCT ATTRIBUTES

Product Type: Fan Unit

Input Voltage AC: 230V min

Package Quantity: 1

Finish: Aluminum-Zinc Plated; Anodized

Material: Сталь; Алюминий

Net Weight: 3.3kg

ADDITIONAL PRODUCT DETAILS

Сетевой кабель заказывается отдельно.

Решения с широким диапазоном входного напряжения (86 ... 264 В перем. тока) доступны по запросу.

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE