


Вентиляторный блок с корпусом для 19-дюймового нагнетательного вентилятора, 2 U, осевой, 230 В перем. тока

CATALOG NUMBER

10713-530

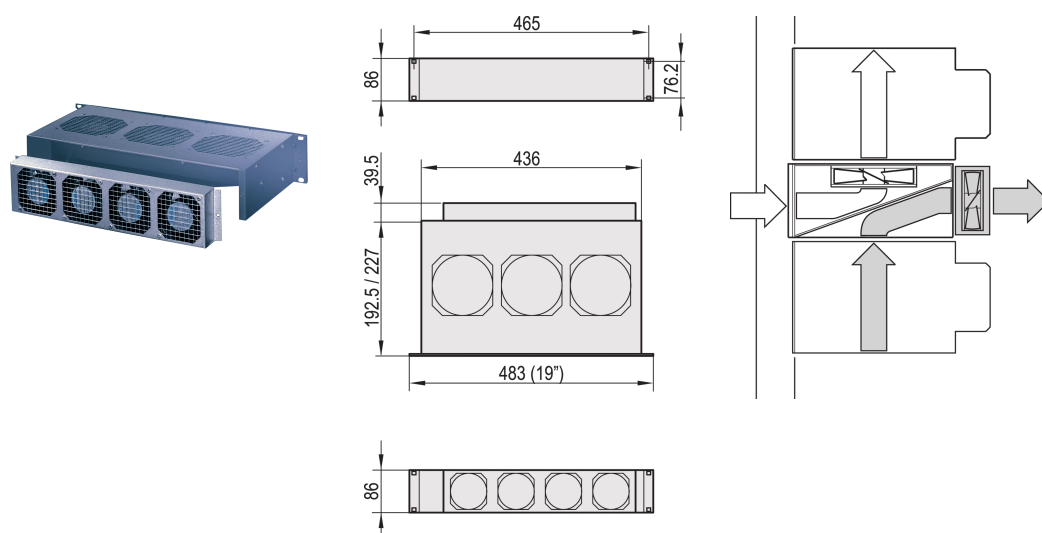

Supplementary fan (built-on) with housing for Schroff pusher fan 2 U. No additional voltage supply necessary: connection is via 19" pusher fan.

CERTIFICATIONS



FEATURES

Дополнительное полезное пространство 2 U: с помощью встроенного вентилятора, компоненты, установленные под 19-дюймовым нагнетательным вентилятором, могут охлаждаться

Дополнительное напряжение питания не требуется: соединение осуществляется через 19-дюймовый нагнетательный вентилятор, формата 2 U

PRODUCT ATTRIBUTES

Product Type: Fan Unit
Type: Fan Tray
Color: Серебристый
Input Voltage AC: 230V
Package Quantity: 1
Net Weight: 1.817kg

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE