


19-дюймовый нагнетательный вентилятор, ширина стойки 2 U, аксиальный, 230 В перем. тока, глубина печатной платы 160 мм, 445–530 м³/ч

CATALOG NUMBER

10713-534

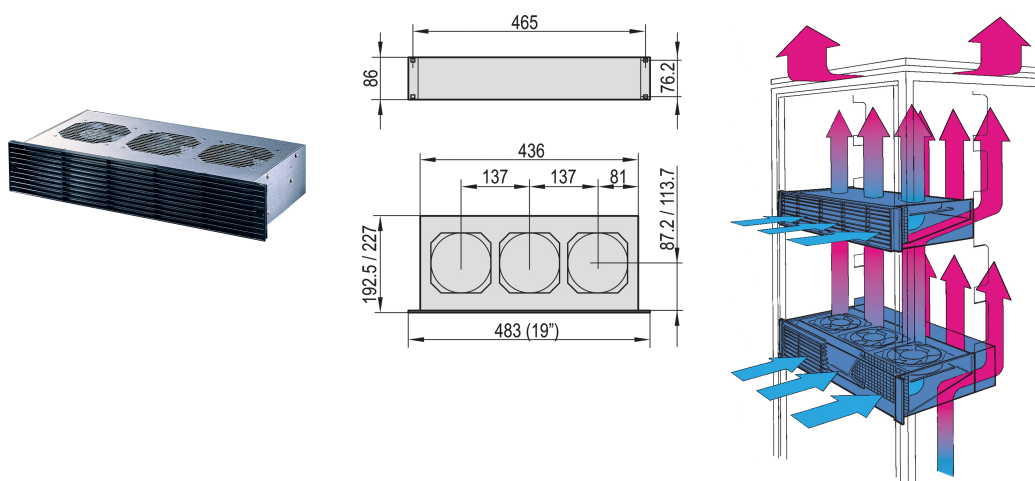

Лоток вентилятора со встроенным нагнетательным вентилятором.

CERTIFICATIONS



FEATURES

Защита от прикосновения в соответствии с DIN EN ISO 13857

Встроенный воздуховод предотвращает накопление тепла в расположенных ниже модулях

Возможность использования в комбинации с блочным каркасом

Возможна комплектация дополнительным вентилятором с задней стороны, 2 U, для активного охлаждения модулей под нагнетательным вентилятором

PRODUCT ATTRIBUTES

Product Type: Fan Unit
Input Voltage AC: 230V
Package Quantity: 1
Finish: Aluminum-Zinc Plated
Material: Сталь; Polypropylene
Net Weight: 4.09kg

ADDITIONAL PRODUCT DETAILS

Сетевой кабель заказывается отдельно.

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE