


19-дюймовый источник питания перем. тока/пост. тока для MicroTCA, без регулирования, двойной полноразмерный

CATALOG NUMBER

11098-392

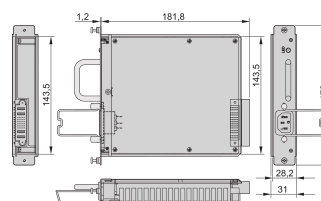

Блок питания 300 MTCA — это исключительно эффективный модуль питания для MicroTCA-систем. Без контроллера PM EMMC, он предназначен для систем MicroTCA без управления оборудованием, а также может использоваться в системах MicroTCA с контроллером PM EMMC на объединительной плате.

CERTIFICATIONS



FEATURES

Широкий диапазон входного напряжения 90 ... 264 В перем. тока

Активная коррекция коэффициента мощности

Конструкция совместима с форматом AdvancedMC Double Full-size

Одножильный токовый общий кабель для резервирования

Соответствует классу В ЭМС по EN 55022

Без контроллера управления питанием MicroTCA

Сетевой вход спереди

PRODUCT ATTRIBUTES

Product Type: Power Supply

Type: 19" Switched-Mode

Works With: MicroTCA Systems

Input Voltage AC: 90 – 264V

Мощность W: 300W

Number of Output Voltages: 2

Voltage 1: 12V

Current 1: 25A

Voltage 2: 3.3V

Current 2: 3A

Rack Width: 6HP

Глубина мм: 186.65mm

Высота мм: 148.3mm

Package Quantity: 1

ADDITIONAL PRODUCT DETAILS

Выходные данные для $T_a = -25 \dots 55^\circ\text{C}$ с принудительным охлаждением 20 куб. фт/мин.

Разъем FCI 51720-10202402AA или Molex 87631-2019

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE