


Монтажный кронштейн для шины 1, 2- полюсная

CATALOG NUMBER

20100-028

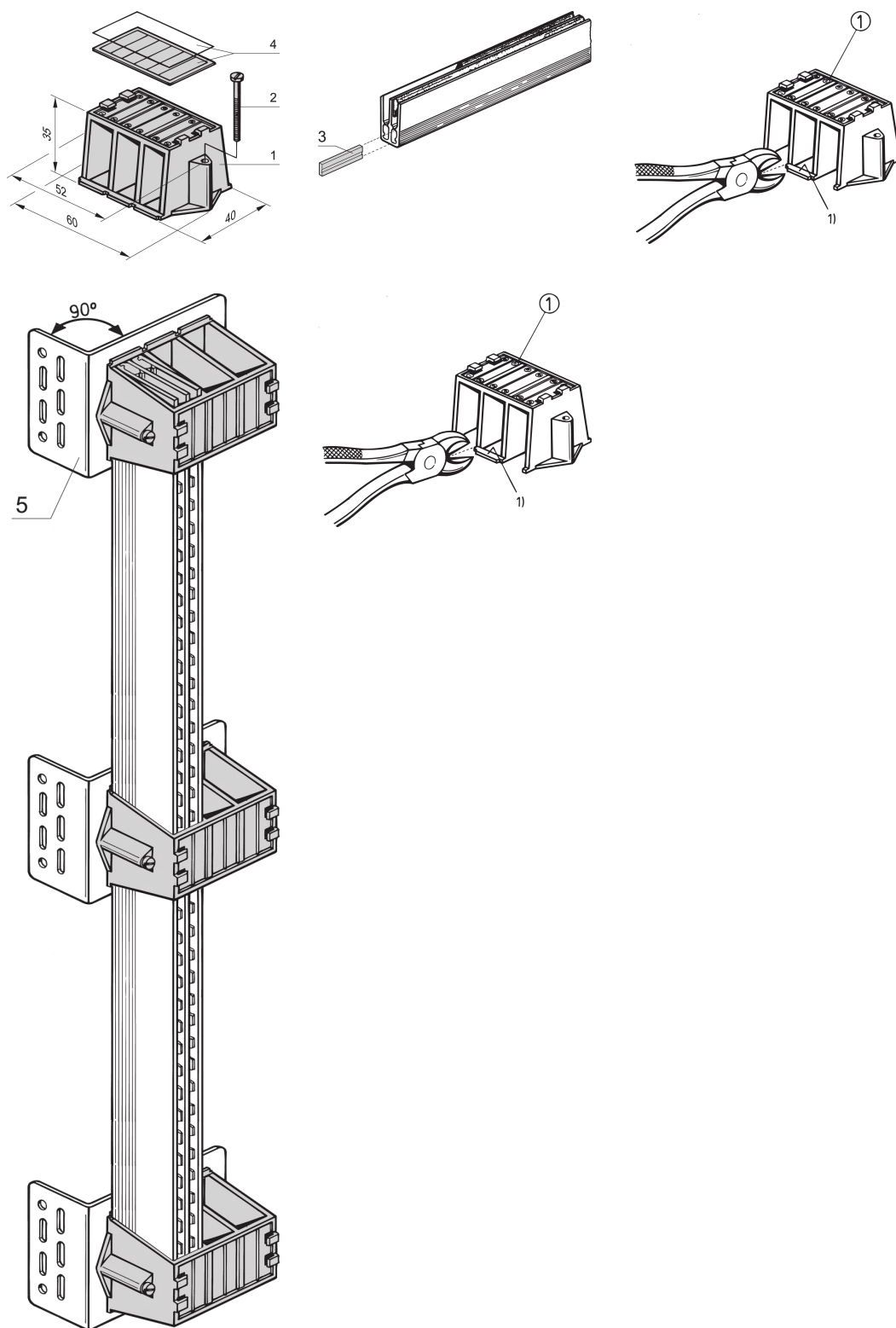

Монтажные кронштейны для шин или модулей шин представляют собой изолированные от цепи нагрузки монтажные блоки для направляющих реек заземления. Также доступны адаптеры с заданными номинальными токами, которые подают ток нагрузки на загрузочные устройства через проводные соединения.

CERTIFICATIONS



FEATURES

Монтажный кронштейн для шины, 2-полюсный

PRODUCT ATTRIBUTES

Product Type: Bracket
Type: Mounting Bracket
Works With: Токоведущая шина
Material: Polyphenylene Ether
Package Quantity: 4
Net Weight: 0.07kg

ADDITIONAL PRODUCT DETAILS

По соображениям устойчивости крепежный кронштейн должен устанавливаться с интервалом в 500 мм.

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE