
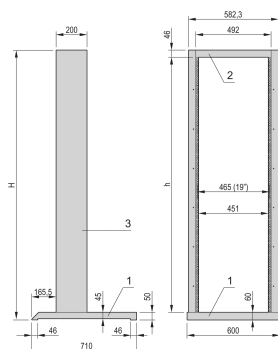


Стационарный цоколь для 19-дюймового шкафа открытого типа Labrack

CATALOG NUMBER

20118-743

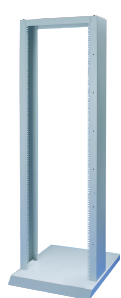

19-дюймовый шкаф Labrack открытого типа может иметь подвижное основание. Чаще всего это решение выбирается для стоек с контрольно-измерительным оборудованием.

CERTIFICATIONS



FEATURES

Решение обычно применяют для вертикальной установки испытательных и измерительных приборов

PRODUCT ATTRIBUTES

Product Type: Rack

Product Family: Лабораторная стойка

Frame Material: Сталь

Ширина мм: 600mm

Глубина мм: 710mm

Static Load: 150kg

Complies With: IEC 60297-3-100

Finish: Powder Coated

Gross Weight: 14.5kg

Material: Сталь

Package Quantity: 1

ADDITIONAL PRODUCT DETAILS

Стойки заказываются отдельно.

В качестве альтернативы 19-дюймовый шкаф с открытой рамой Labrack может иметь неподвижное основание.

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE