


19-дюймовая полка для оборудования, высота 2 U, RAL 7035

CATALOG NUMBER

20118-785

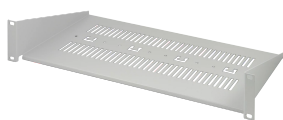

19-дюймовые полки для оборудования nVent SCHROFF с максимальной нагрузкой до 10 кг позволяют компактно располагать оборудование в шкафу.

CERTIFICATIONS



FEATURES

Монтажная высота 2 U

Допустимая статическая нагрузка 10 кг

PRODUCT ATTRIBUTES

Ширина мм: 447mm

Глубина мм: 238mm

Package Quantity: 1

Color: Light Grey

Color Code: RAL 7035

Finish: Powder Coated

Material: Сталь

Product Type: Полка с креплением на каркасе

Type: Equipment Shelf

Gross Weight: 1.78kg

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE