


Система VMEbus, высота 4 U, 8 слотов, бескорпусный источник питания

CATALOG NUMBER

20836-415

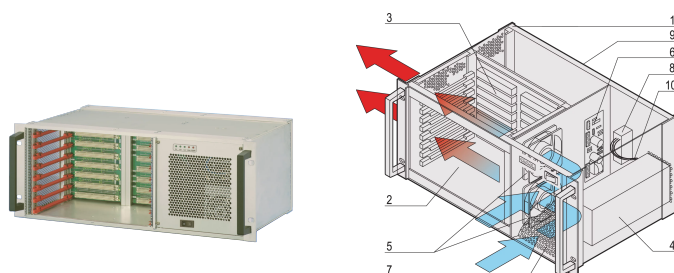

Система VME для 8 горизонтально установленных печатных плат VME 6 U, 160 мм. Питание системы осуществляется от бескорпусного источника питания. Модуль управления вентилятором контролирует работу вентиляторов, следит за температурой и напряжением.

CERTIFICATIONS



FEATURES

Система в соответствии с IEC60297-3-101, -102, -103 IEEE 1101.1, 1101.10/11; объединительная плата соответствует требованиям VITA 1.1-1994

Блоки питания, бескорпусного типа, 444 Вт (400 Вт при < 180 В перем. тока)

Отвод тепла 2 вентиляторами, воздушный поток направляется спереди в левую сторону; управление температурой с помощью модуля управления вентилятором (FCM)

Модуль индикации рабочего напряжения (пост. ток), аварийные сигналы от вентиляторов и датчиков температуры

Backplane VME 8 slot, 6 U, J1/J2 monolithic in accordance with VITA 1-1994

PRODUCT ATTRIBUTES

Product Type: System

Number of Slots: 8

Type: 19" Rack Mount

Backplane Type: 6 U VME64

Data Transfer: VME64; VME2eSST

Power per Slot: 30W

Input Voltage AC: 100 – 240V

Airflow Direction: Front to Left

Rack Height: 4U

Power Supply Type: Open Frame

Power Supply Included: Да

Rear I/O: Нет

Complies With: ANSI/VITA 1.1-1994

Глубина мм: 277.5mm

Высота мм: 177mm

Ширина мм: 449mm

Мощность W: 350W

Package Quantity: 1

ADDITIONAL PRODUCT DETAILS

Модифицированные системы доступны по запросу.

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:

nvent.com/schroff



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE