


**Передняя панель, модернизированное
экранирование, высота 3 U, ширина стойки
84 HP**

CATALOG NUMBER

20848-097

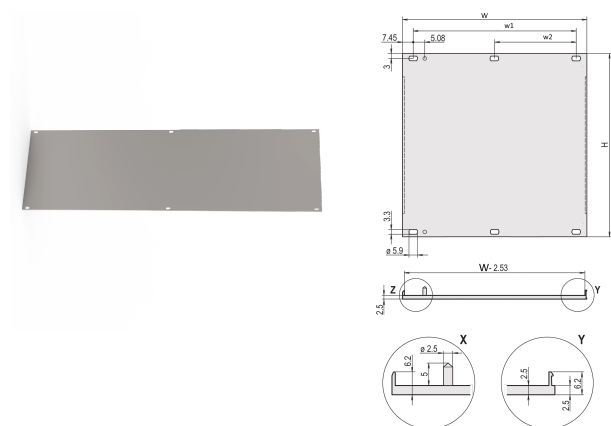

Текстильный ЭМС-уплотнитель для передней панели

CERTIFICATIONS



FEATURES

U-образный профиль, передняя панель, алюминий, 2,5 мм, лицевая поверхность анодированная, тыльная поверхность электропроводящая

Для текстильного уплотнителя ЭМС

PRODUCT ATTRIBUTES

Rack Height: 3U

Rack Width: 84HP

Package Quantity: 1

Аксессуар Тип: Передняя панель

Mounting: Screw-on Front

EMC Gasket Type: Textile

Front Finish: Anodized

Rear Finish: Conductive

Treated Edges: Нет

Complies With: IEC 60297-3-101; IEEE 1101.1/10

Глубина мм (D): 2.5mm

EMC Shielding: No (Retrofittable)

Finish: Anodized; Passivated

Высота мм (H): 128.4mm

Material: Алюминий

Product Type: Передняя панель

Type: Front Panel without Handle

Ширина мм (W): 426.4mm

Net Weight: 0.397kg

ADDITIONAL PRODUCT DETAILS

Крепежный материал (втулки, винты с проточкой) заказывается отдельно.

Есть разница в покрытии между 2 ... 12 HP и 14 ... 84 HP.


от 2 до 12 HP: цельный U-образный профиль

Текстильная ЭМС-прокладка заказывается отдельно.

Standard pack quantity: 2 to 28HP: 5 шт., 42 to 84 HP: 1 шт., supplied in standard pack quantities (SPQ) only.

14 ... 84 HP: multi-part U-profile (front panel with crimped profiles).

DIAGRAMS

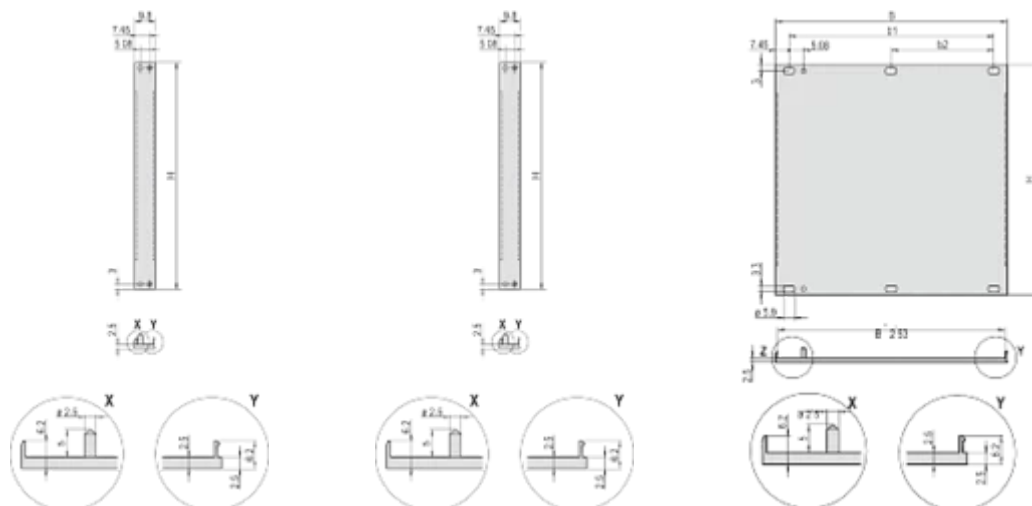

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE