


19-дюймовое крепление для панели/направляющей Euro rack, 38 U, AlZn

CATALOG NUMBER

22117-356

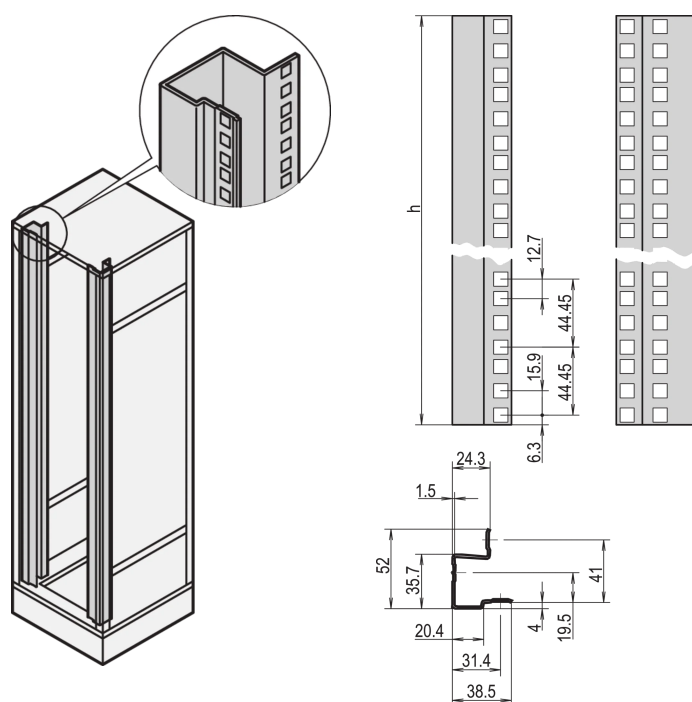

Крепление для направляющей с регулируемым шагом.

CERTIFICATIONS



FEATURES

Для монтажа с регулируемой глубиной

сталь, 1,5 мм, с перфорацией EIA

Для монтажа третьего 19-дюймового профиля необходимы 1 пара 19-дюймовых монтажных профилей и 2 пары заглубляющих распорок

PRODUCT ATTRIBUTES

Rack Height: 38U
Material: Сталь
Finish: Aluminum-Zinc Plated
Package Quantity: 2
Высота мм: 1798mm
Product Family: Eurorack
Product Type: Slide Mount
Type: 19" Panel Slide Mount
Net Weight: 4.25kg

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE