


Объединительная плата VMEbus с уровнем J1/J2, высота 6 U, 8 слотов

CATALOG NUMBER

23001-068

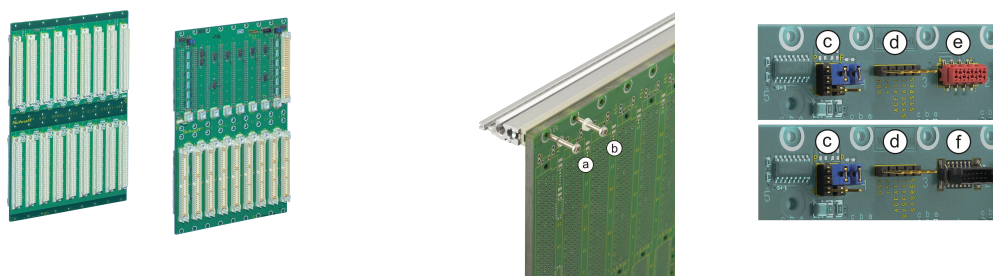

Объединительные платы nVent SCHROFF VMEbus обладают выдающимися характеристиками подавления высокочастотных помех и очень высокими показателями наработки на отказ благодаря керамическим конденсаторам и технологии изготовления SMD.

CERTIFICATIONS



FEATURES

В соответствии со стандартом ANSI/VITA 1-1994 VME64

Монолитная кроссплата, 6 U, с профилем J1 и J2

Возможно соединение и разъединение цифрового заземления (Digital-GND) и заземления шасси (Chassis-GND) с помощью резьбового соединения

Согласование активное/пассивное, переключается перемычкой; предварительно установлено пассивное согласование

Электронная автоматическая группировка устройств Daisy Chain (EDC)

Подача питающего напряжения через соединение Powerbugs (кольцевой наконечник M4) или FASTON

PRODUCT ATTRIBUTES

Product Type: Объединительная плата
Number of Slots: 8
Rack Height: 6U
Backplane Type: VMEbus, J1/J2, with EDC
System Slot: Slot 1 Left
Slot Width: 4HP
Connector Type: DIN 41612, C96
Power Connector Type: Power Bugs for M4 Cable Lugs
Utility Connector Type: MicroMatch, 8-pin, 5-pin Header
Высота мм: 263.4mm
Ширина мм: 161.1mm
Gross Weight: 0.795kg
Package Quantity: 1

ADDITIONAL PRODUCT DETAILS

Другие конфигурации доступны по запросу.

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE