


Винт со сферо-цилиндрической головкой, Torx, диаметр 2,5 мм, длина 9,3 мм, саморез, стальной оцинкованный

CATALOG NUMBER

24560-141

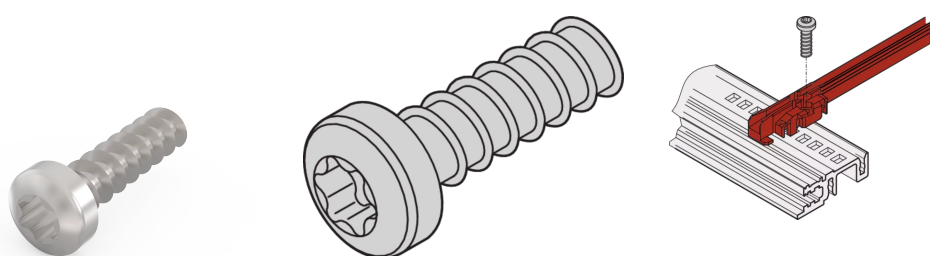

Винты с потайной головкой.

CERTIFICATIONS



FEATURES

Винт с потайной головкой с Torx, самоформирующийся

Для монтажа трапецевидных ручек на передней панели сменных блоков PRO каркасного типа

PRODUCT ATTRIBUTES

Длина мм: 9.3mm

Package Quantity: 100

Thread Size: M2.5

Finish: Zinc Plated

Material: Сталь

Product Family: Frame Type Plug-In Unit

Product Type: Screw

Type: Panhead Screw

Works With: Направляющие для плат

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE