
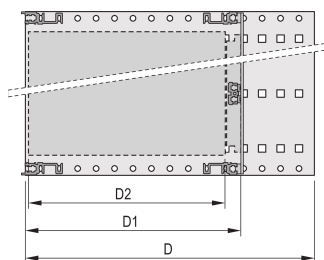
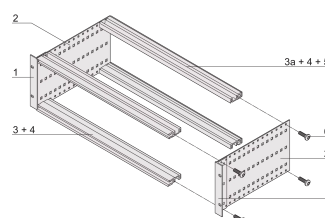


Комплект 19-дюймового блочного каркаса EurorasPRO для объединительной платы, усиленный, модернизированное экранирование, 3 U, 355 мм

CATALOG NUMBER

24563-164

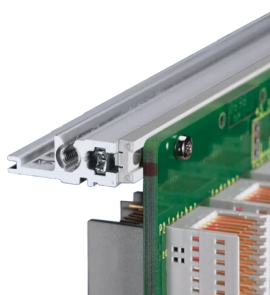

Задний горизонтальный рельс для монтажа объединительной платы с изолирующей полосой

CERTIFICATIONS



FEATURES

Горизонтальный рельс типа H "heavy"

Устойчивость к ударным нагрузкам и вибрации до 5 g

IP 20 в соответствии с IEC 60529

Протокол испытаний на устойчивость к ударным нагрузкам и вибрации: немецкие железнодорожные стандарты BN 411002, BN 411003

Внутренние и внешние размеры соответствуют IEC 60297-3-100, -101, IEEE 1101.1

Макс. вес устанавливаемого оборудования до 15 кг

Вариант исполнения без передних ручек

Поставляется в компактной плоской упаковке

PRODUCT ATTRIBUTES

Rack Height: 3U

Глубина мм: 355mm

Package Quantity: 1

For Mounting: Объединительная плата

Board Depth: 160mm; 220mm; 280mm; 340mm

EMC Gasket Type: Textile

Shock and Vibration Tolerance: 5g (force)

Handle Included: Нет

Mounting: Rack

Complies With: IEC 60297-3-103

EMC Shielding: Нет

Finish: Anodized; Passivated

Material: Алюминий

Product Type: Subrack/Chassis

Rack Width: 84HP

Static Load: 15kg

Net Weight: 1.49kg

ADDITIONAL PRODUCT DETAILS

Индивидуальная конфигурация: широкий выбор вариантов по высоте, ширине и глубине; направляющие для самых разных применений; выбор вариантов внутреннего оснащения, принадлежностей и монтажного материала.

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE