


**Набор для монтажа вставных блоков
рамного типа PRO, перфорированные
крышки, 1 разъем, высота 3 U, ширина
стойки 14 HP, 167 мм**

CATALOG NUMBER

24812-214

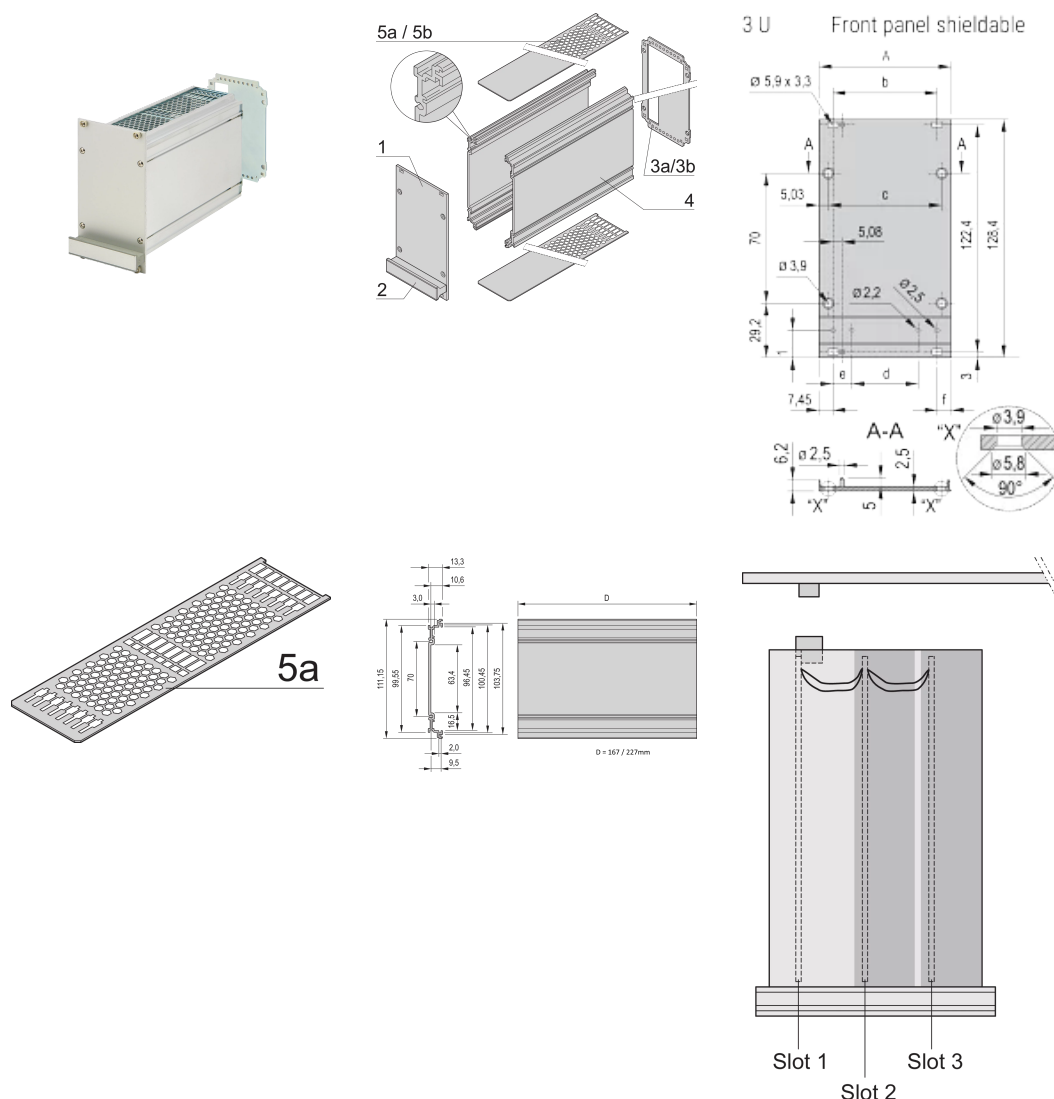

Сменный блок рамного типа, незранированный, перфорированная верхняя/нижняя крышка, задняя панель с вырезом для одного разъема.

CERTIFICATIONS



FEATURES

Экструдированные боковые панели справа и слева, с канавками для вставки печатной платы (стандартное положение платы только слева)

Задняя стенка с выемкой для одного разъема (соответствует EN 60603, DIN 41612, типы конструкции: B, C, D, F, H, Q, R, S)

Верхняя крышка с перфорацией, для направляющих (воздушный поток прикл. 60 %); направляющие заказываются отдельно

PRODUCT ATTRIBUTES

Rack Height: 3U

Rack Width: 14HP

Package Quantity: 1

Handle Type: Trapezoid

Rear Panel Type: Single Connector Cut-Out

Cover Plate Type: Cover Plate with Perforation for Guide Rails

Front Finish: Anodized

Rear Finish: Anodized

Cooling: С перфорацией

Глубина мм (D): 167mm

EMC Shielding: Нет

Finish: Anodized

Material: Алюминий

Product Type: Cassette


Type: Frame Type Plug-in Units PRO

Gross Weight: 0.532kg

ADDITIONAL PRODUCT DETAILS

To fit further boards without rear connector, guide rail (part no. 24812-301) and 'Board fixing from slot 2' (part no. 24812-301 + screw part no. 24560-178) are required, 2 guide rails, 2 rear panel holders and board fixing for slot 1 and one slot 2 are already included.

DIAGRAMS

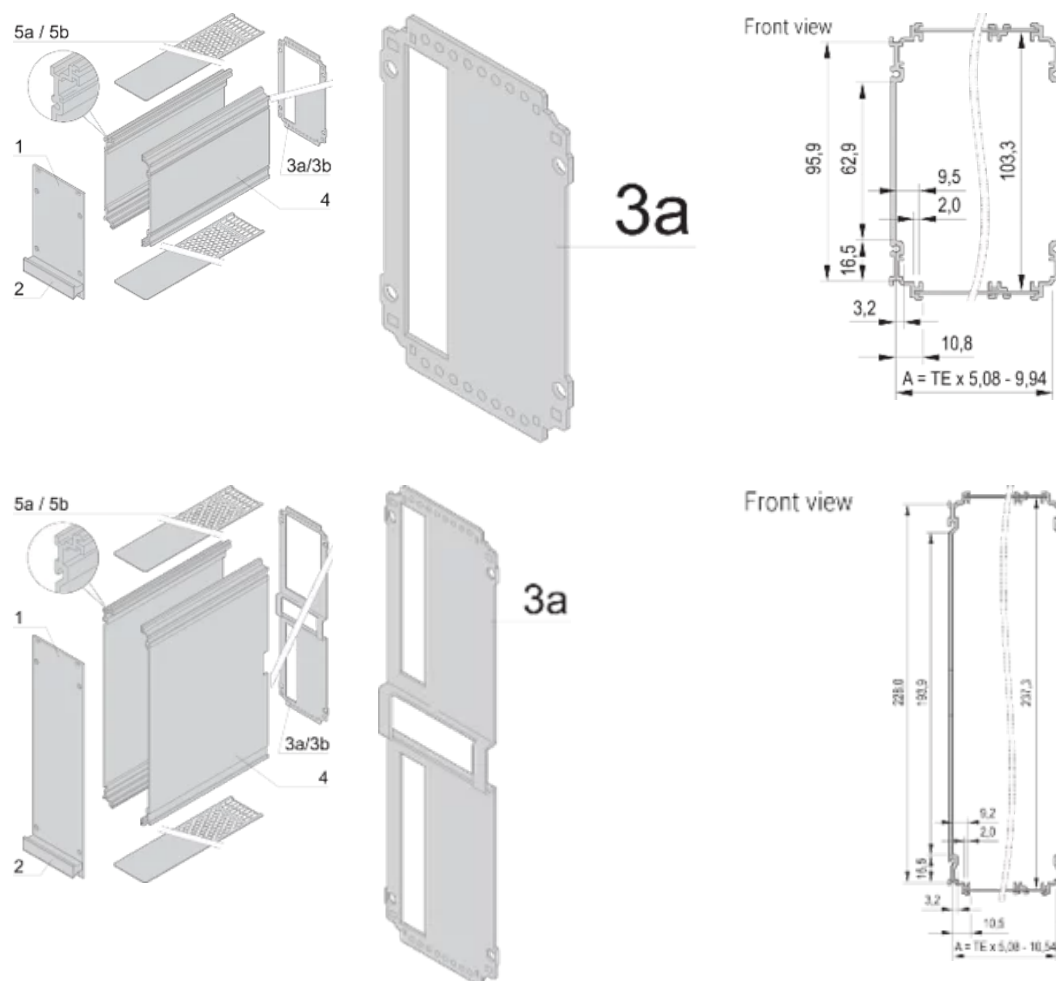

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:

nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE