






Набор для монтажа вставных блоков рамного типа PRO, экранированный, перфорированный, 1 разъем, высота 3 U, ширина стойки 12 HP, 167 мм

CATALOG NUMBER

24813-212

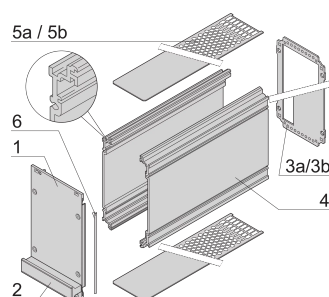

3 U Front panel shieldable

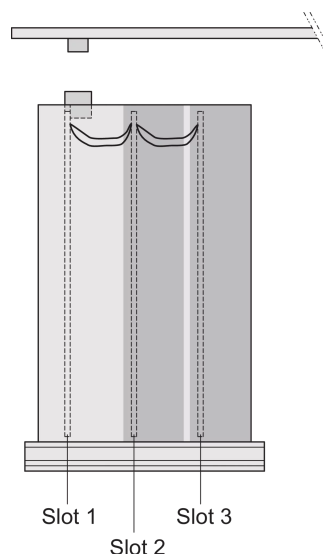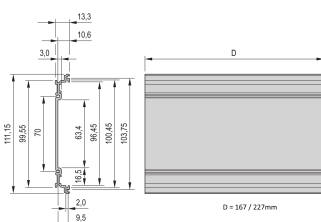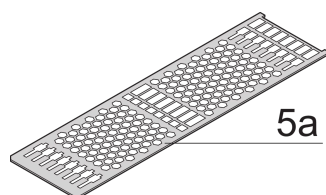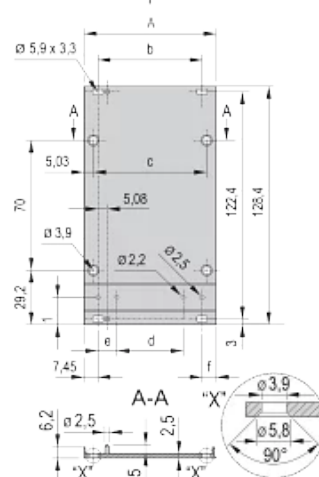

Защищает печатную плату от механических повреждений и электростатического разряда; для европлат; задняя панель с одним вырезом для одного разъема.

CERTIFICATIONS



FEATURES

Верхняя крышка с перфорацией, для направляющих (воздушный поток приibl. 60 %)

Задняя стенка с выемкой для одного разъема (соответствует EN 60603, DIN 41612, типы конструкции: B, C, D, F, H, Q, R, S)

Экструдированные боковые стенки с пазом справа и слева, для ввода печатной платы (стандартное положение платы только в левой боковой стенке)

PRODUCT ATTRIBUTES

Rack Height: 3U

Rack Width: 12HP

Глубина мм (D): 167mm

Handle Type: Trapezoid

Package Quantity: 1

EMC Gasket Type: Textile

Rear Panel Type: Single Connector Cut-Out

Cover Plate Type: Cover Plate with Perforation for Guide Rails

Front Finish: Anodized

Rear Finish: Conductive

Cooling: С перфорацией

EMC Shielding: Да

Finish: Anodized; Passivated

Material: Алюминий

Product Type: Cassette


Type: Frame Type Plug-in Units PRO

ADDITIONAL PRODUCT DETAILS

Направляющие заказываются отдельно.

To fit further boards without rear connector, guide rail (part no. 24812-301) and 'Board fixing from slot 2' (part no. 24812-301 + screw part no. 24560-178) are required, 2 guide rails, 2 rear panel holders and board fixing for slot 1 and one slot 2 are already included.

DIAGRAMS

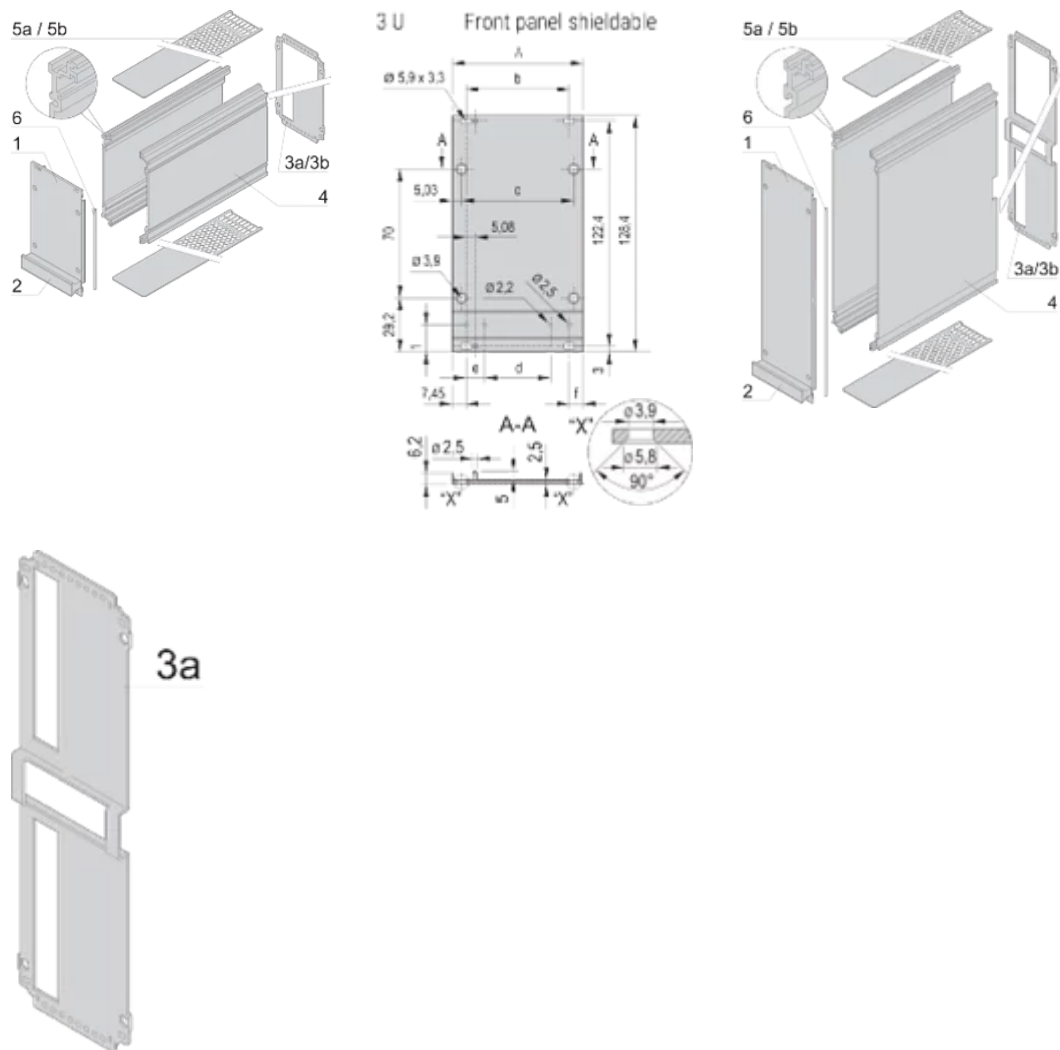

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE