


**Набор для монтажа вставных блоков  
рамного типа PRO, экранированный,  
перфорированный, несколько разъемов,  
высота 3 U, ширина стойки 10 HP, 227 мм**

CATALOG NUMBER

**24813-360**

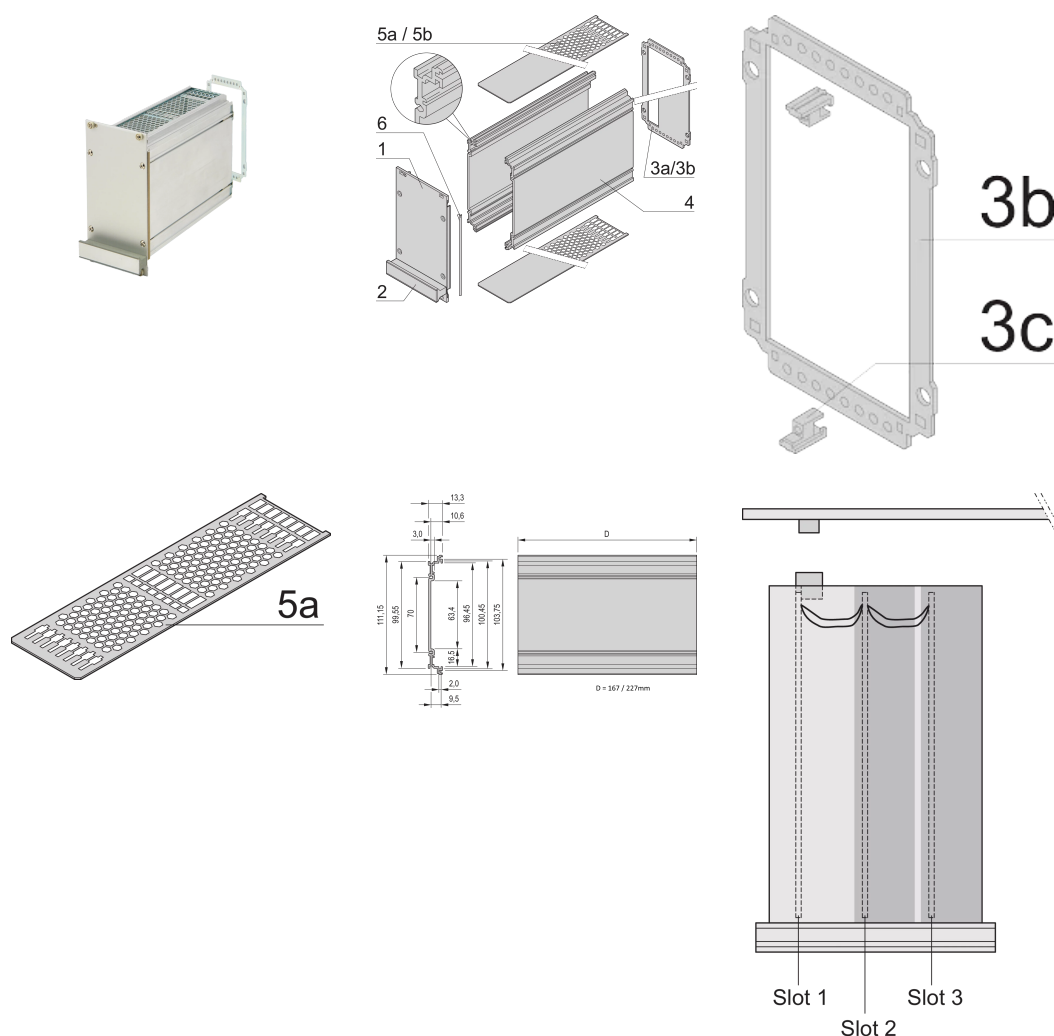

Защищает печатную плату от механических повреждений и электростатического разряда; для европлат; задняя панель с вырезами для нескольких разъемов.

## CERTIFICATIONS

---



## FEATURES

---

Верхняя крышка с перфорацией, для направляющих (воздушный поток прибл. 60 %)

Задняя панель с вырезами для нескольких разъемов

Экструдированные боковые стенки с пазом справа и слева, для ввода печатной платы (стандартное положение платы только в левой боковой стенке)

## PRODUCT ATTRIBUTES

---

Rack Height: 3U

Rack Width: 10HP

Package Quantity: 1

Handle Type: Trapezoid

EMC Gasket Type: Textile

Rear Panel Type: Multiple Connector Cut-Out

Cover Plate Type: Cover Plate with Perforation for Guide Rails

Front Finish: Anodized

Rear Finish: Anodized

Cooling: С перфорацией

Глубина мм (D): 227mm

EMC Shielding: Да

Finish: Anodized; Passivated

Material: Алюминий

Product Type: Cassette

Type: Frame Type Plug-in Units PRO


## ADDITIONAL PRODUCT DETAILS

---

Направляющие заказываются отдельно.

To fit further boards without rear connector, guide rail (part no. 24812-301) and 'Board fixing from slot 2' (part no. 24812-301 + screw part no. 24560-178) are required, 2 guide rails, 2 rear panel holders and board fixing for slot 1 and one slot 2 are already included.

DIAGRAMS

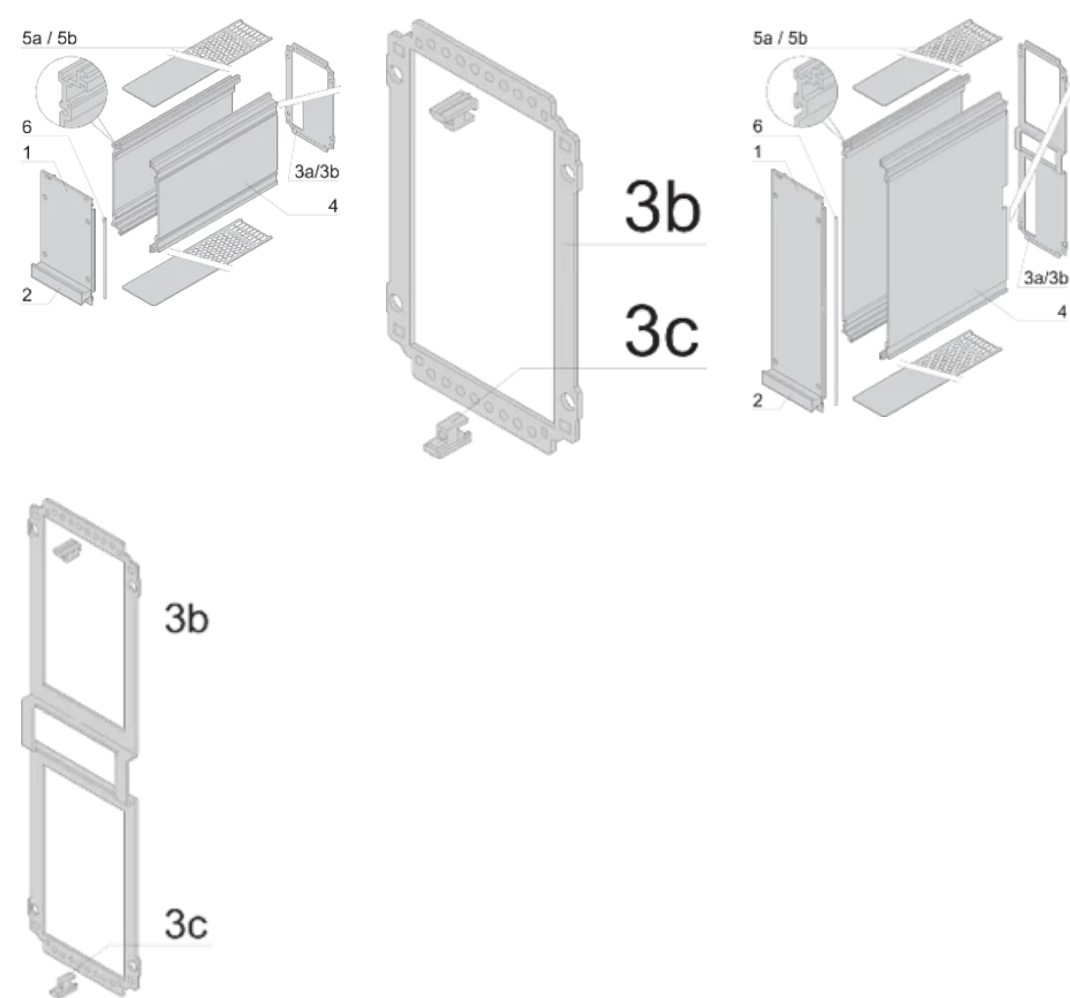

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause

North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

Middle East & India

Dubai, United Arab  
Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)



Our powerful portfolio of brands:

CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE