


**Набор для монтажа вставных блоков
рамного типа PRO, экранированный,
перфорированный, несколько разъемов,
высота 3 U, ширина стойки 21 HP, 227 мм**

CATALOG NUMBER

24813-371

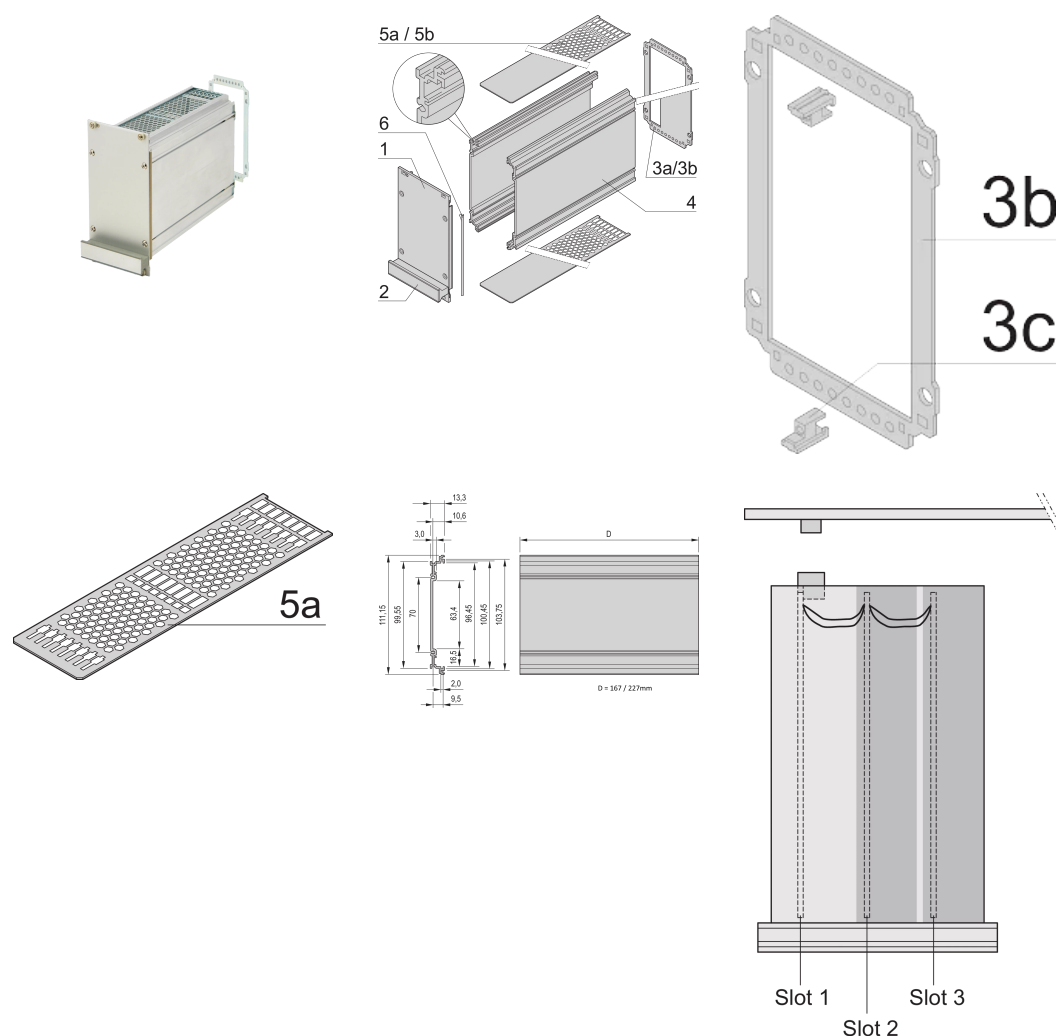

Защищает печатную плату от механических повреждений и электростатического разряда; для европлат; задняя панель с вырезами для нескольких разъемов.

CERTIFICATIONS



FEATURES

Верхняя крышка с перфорацией, для направляющих (воздушный поток прибл. 60 %)

Задняя панель с вырезами для нескольких разъемов

Экструдированные боковые стенки с пазом справа и слева, для ввода печатной платы (стандартное положение платы только в левой боковой стенке)

PRODUCT ATTRIBUTES

Rack Height: 3U

Rack Width: 21HP

Package Quantity: 1

Handle Type: Trapezoid

EMC Gasket Type: Textile

Rear Panel Type: Multiple Connector Cut-Out

Cover Plate Type: Cover Plate with Perforation for Guide Rails

Front Finish: Anodized

Rear Finish: Anodized

Cooling: С перфорацией

Глубина мм (D): 227mm

EMC Shielding: Да

Finish: Anodized; Passivated

Material: Алюминий

Product Type: Cassette

Type: Frame Type Plug-in Units PRO

Net Weight: 0.79kg

ADDITIONAL PRODUCT DETAILS

Направляющие заказываются отдельно.

To fit further boards without rear connector, guide rail (part no. 24812-301) and 'Board fixing from slot 2' (part no. 24812-301 + screw part no. 24560-178) are required, 2 guide rails, 2 rear panel holders and board fixing for slot 1 and one slot 2 are already included.

DIAGRAMS



WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE