


Алюминиевый корпус IP-PRO, ЭМС-экранирование, высота 180 мм, ширина 402 мм, глубина 310 мм, IP65

CATALOG NUMBER

26880-013

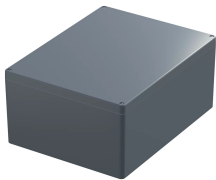

Корпус IP-Pro Alu EMC – корпус для надежной защиты от воды, пыли и электромагнитных помех для чувствительной электроники в неблагоприятных условиях. Испытан и сертифицирован для применения в условиях с более высокими требованиями в отношении ударных нагрузок и вибрации.

FEATURES

Алюминиевый литой корпус доступен в 15 различных размерах, с порошковым покрытием для использования вне помещений, цвет: серебристо-серый (RAL 7001)

С ЭМС-экранированием

Устойчивость к ударным нагрузкам и вибрации в соответствии с EN 61373 Кат. 2 и AREMA класс I

Защита IK 09 от внешних механических воздействий в соответствии с IEC 62262

Температурный диапазон корпуса от –40 до +90°C

Depending on size, protection class up to IP67 according to EN 60529

PRODUCT ATTRIBUTES

Высота мм: 180mm

Ширина мм: 402mm

Глубина мм: 310mm

Protection Rating: IP65

Package Quantity: 1

Color: Silver Grey

Color Code: RAL 7001

Finish: Powder Coated

Material: Алюминий

Product Family: IP-PRO ALU EMC

Product Type: Small Form Factor Case

Shape: Прямоугольный

Type: Rugged

Net Weight: 7.5kg

ADDITIONAL PRODUCT DETAILS

По вопросам механических модификаций, инновационных решений для крепления печатных плат и кабелей, а также концепций охлаждения просим связываться с нами.

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE