


Дверной шарнирный кронштейн Novastar для укороченной двери, для универсальной передней или задней двери повышенной прочности

CATALOG NUMBER

27230-098

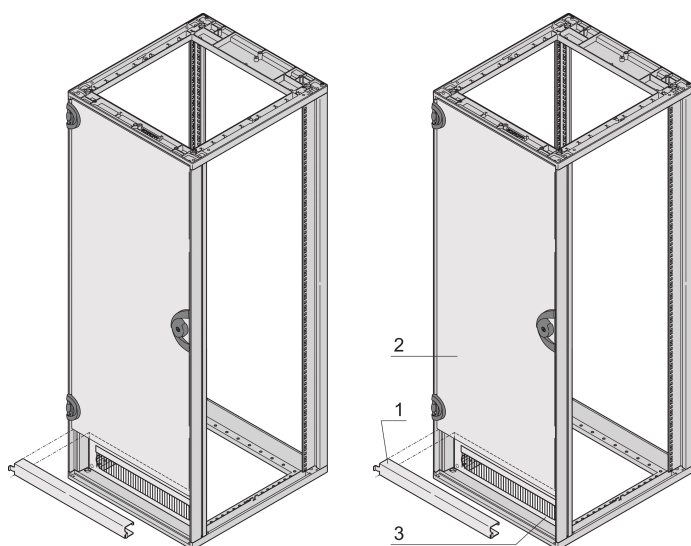

Шарнирный кронштейн для укороченных дверей, усиленного типа и Slim Line, передних или задних.

CERTIFICATIONS



FEATURES

Монтаж (необходимое монтажное пространство 1 U) может быть выше или ниже укороченной двери

Для установки стальных дверей на неполную высоту шкафа

Требуется место для установки 1 U

Зазор можно закрыть 19-дюймовыми передними панелями или панелью кабельного ввода (3 U или 4 U)

PRODUCT ATTRIBUTES

Ширина мм: 553mm

Material: Сталь

Works With: Cabinet

Package Quantity: 1

Color: Black Grey

Color Code: RAL 7021

Finish: Powder Coated

Высота мм: 44.45mm

Product Family: Novastar

Product Type: Bracket

Type: Bracket

Gross Weight: 2kg

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE