


19-дюймовая передняя панель, высота 1 U, 3 мм, анодированный алюминий, необработанные кромки

CATALOG NUMBER

30219-098

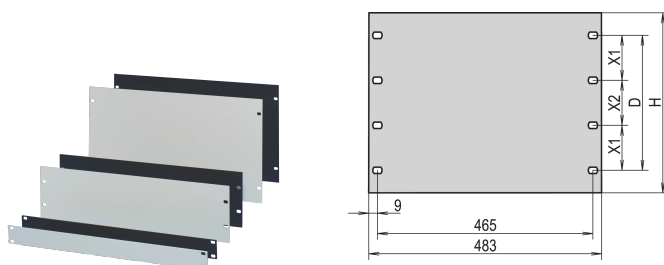

Передние панели выполнены из анодированного алюминия, цвет светло-серый (RAL 7035) или темно-серый (RAL 7021).

CERTIFICATIONS



FEATURES

Алюминий анодированный, 3 мм

PRODUCT ATTRIBUTES

Rack Height: 1U

Глубина мм (D): 3mm

Аксессуар Тип: Передняя панель

Mounting: Screw-on Front

Finish: Anodized

Front Finish: Anodized

Package Quantity: 1

Rear Finish: Anodized

Treated Edges: Нет

EMC Shielding: Нет

Высота мм (H): 43.6mm

Material: Алюминий

Product Type: Передняя панель

Rack Width: 95HP

Type: 19" Front Panel

Ширина мм (W): 483mm

ADDITIONAL PRODUCT DETAILS

Монтажный комплект для сборки на 19 дюймов заказывается отдельно.

DIAGRAMS



WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE