


Монтажный кронштейн печатной платы для высокочастотного вставного модуля рамного типа, верхний

CATALOG NUMBER

30809-701

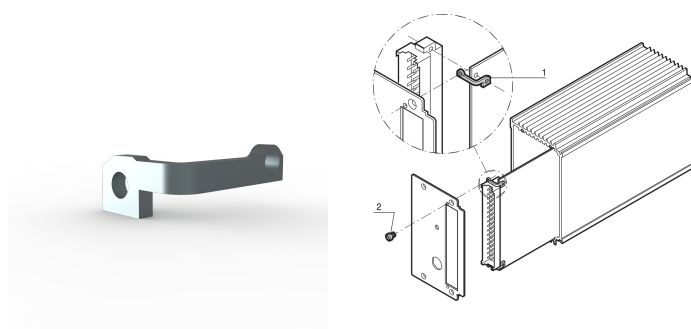

Кронштейны позволяют пользователю крепить печатную плату к задней панели.

CERTIFICATIONS



FEATURES

Кронштейн для установки платы на заднюю панель

PRODUCT ATTRIBUTES

Package Quantity: 1

Глубина мм (D): 13.5mm

Высота мм (H): 5.8mm

Material: Нержавеющая сталь

Product Family: HF Frame Type Plug-In

Product Type: Bracket

Type: PCB Guide

Ширина мм (W): 9.8mm

Works With: Cassettes


Bracket Type: Top

Thread Type: Metric

ADDITIONAL PRODUCT DETAILS

Винты заказываются отдельно.

DIAGRAMS

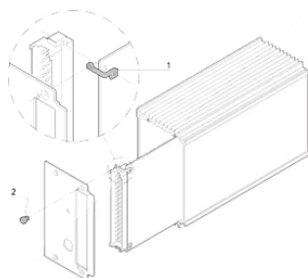

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE