


# Задний горизонтальный рельс типа АВ для направляющих задних печатных плат ввода/вывода, 84 HP

## CATALOG NUMBER

**34561-584**

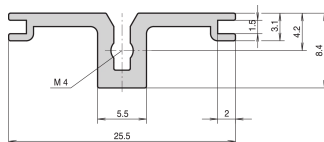

Combinations of horizontal rails and side panels

“+” = can be combined, “-” = combination not recommended

|                 | Light r. L | Standard r. L | Heavy r. L | Rugged r. L |
|-----------------|------------|---------------|------------|-------------|
| Standard r. R   | -          | +             | +          | +           |
| Heavy r. R      | +          | +             | +          | +           |
| Light r. R      | +          | +             | -          | -           |
| Horizontal rail | +          | +             | -          | -           |

Light r. L: Light r. R: Standard r. L: Heavy r. L: Rugged r. L: Standard r. R: Heavy r. R: Light r. R: Horizontal rail

Горизонтальная рейка из алюминиевого экструдированного профиля типа АВ (АВ = опора), для задних направляющих ввода/вывода, с анодированной поверхностью и проводящей контактной поверхностью. Подходят для RatiopacPRO/-AIR и EuropacPRO/-rugged).

## CERTIFICATIONS



## FEATURES

Для CompactPCI в зоне задней панели ввода-вывода

Для расширения 2 × 3 U, требуются 2 горизонтальные рейки типа АВ

Алюминиевый экструдированный профиль, анодированная поверхность, электропроводящая контактная поверхность, с маркировкой HP

## PRODUCT ATTRIBUTES

Rack Width: 84HP

Package Quantity: 1

Finish: Anodized

Длина мм: 431.8mm

Material: Алюминий

Product Family: EuropacPRO; RatiopacPRO; RatiopacPRO AIR; CompacPRO; PropacPRO

Product Type: Горизонтальный рельс

Type: Type AB

Works With: Блочный каркас; Coffrets

## ADDITIONAL PRODUCT DETAILS

Поставка исключительно в размере товарной партии. Цена указана за отдельную единицу.

Обратите внимание, что поставки доступны в указанных стандартных товарных партиях (товарная партия, например, 5 шт., 10 шт., 50 шт. и т. д.). Другие объемы заказов (например, 2 шт.) могут округляться вверх до следующего возможного размера стандартной товарной партии.

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Middle East & India

Dubai, United Arab  
Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)



Our powerful portfolio of brands:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**