
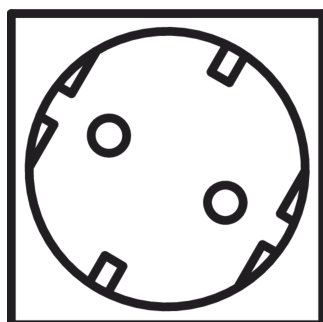


Блок розеток, SCHUKO/UTE, локальный дисплей, 6 x розеток SCHUKO/UTE

CATALOG NUMBER

60110-294

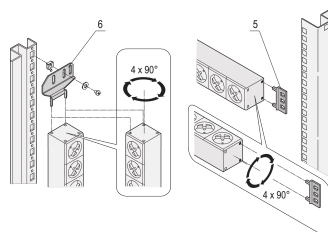

Блок распределения питания со встроенным измерением мощности. Полученные данные о мощности отображаются на встроенном дисплее.

CERTIFICATIONS



FEATURES

Встроенная функция измерения и отображение на локальном дисплее

Панель электропитания с розетками SCHUKO

Монтажная высота 1 U

При установке панель электропитания можно развернуть в любую сторону (с шагом 90°)

Возможен горизонтальный и вертикальный монтаж

Функции измерения: напряжение, сила тока, мощность, частота, коэффициент мощности

PRODUCT ATTRIBUTES

Product Type: Панели электропитания

Socket Type: SCHUKO

Socket Quantity: 6

Color: Серый

Switched Outlets: Нет

Длина мм: 438.5mm

Voltage AC: 230V

Глубина мм: 44mm

Finish: Anodized

Gross Weight: 0.886kg

Material: Алюминий; Polyamide

Package Quantity: 1

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE