


Блок розеток, IEC C13, со встроенным измерением мощности

CATALOG NUMBER

60110-296

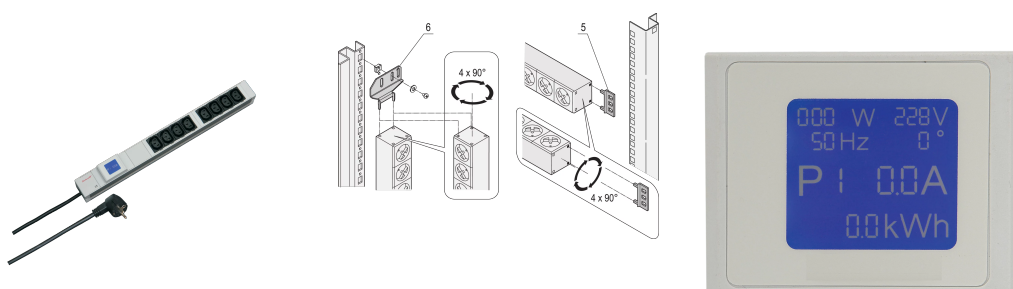

3 2.77kW 230V 4
2 50Hz 15° 5
1 P 12.5A 6
1585.9 kWh 7

Блок распределения питания со встроенным измерением мощности. Полученные данные о мощности отображаются на встроенном дисплее.

CERTIFICATIONS



FEATURES

При установке панель электропитания можно развернуть в любую сторону (с шагом 90°)

Монтажная высота 1 U

Встроенная функция измерения и отображение на локальном дисплее

Панель электропитания с розетками IEC 60320-C13

Возможен горизонтальный и вертикальный монтаж

PRODUCT ATTRIBUTES

Product Type: Панели электропитания
Socket Type: IEC C13
Socket Quantity: 8
Color: Серый
Switched Outlets: Да
Длина мм: 438.5mm
Voltage AC: 230V
Глубина мм: 44mm
Material: Алюминий; Polyamide
Package Quantity: 1

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE