


# Разделительная панель EuropacPRO

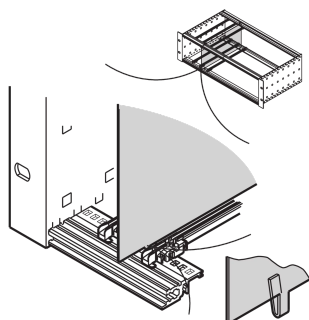

Разделительная панель позволяет пользователю создать отдельную секцию внутри блочного каркаса или корпуса. Панель можно вставить в отверстия горизонтальных реек. Блочные каркасы или корпуса необходимо демонтировать, если будет установлена панель.

## CERTIFICATIONS



## FEATURES

Монтаж посредством фиксации на горизонтальных рейках

Требуемое пространство со стороны монтажа элементов: 2,0 мм

Монтаж зависит от способа уплотнения (контактная пружина из нержавеющей стали или текстильный ЭМС-уплотнитель)

## SPECIFICATIONS

|                        |                   |
|------------------------|-------------------|
| <b>Product Family:</b> | EuropacPRO        |
| <b>Product Type:</b>   | Side Panel        |
| <b>Material:</b>       | Нержавеющая сталь |
| <b>Works With:</b>     | Блочный каркас    |

Table 1/1

| Catalog Number | Rack Height | Package Quantity | Глубина мм | Длина мм | Quick Ship |
|----------------|-------------|------------------|------------|----------|------------|
| 34562-761      | 3U          | 1                | 160mm      | 160mm    | No         |
| 34562-764      | 6U          | 1                | 220mm      | 220mm    | No         |

| Catalog Number | Rack Height | Package Quantity | Глубина мм | Длина мм | Quick Ship |
|----------------|-------------|------------------|------------|----------|------------|
| 34562-763      | 6U          | 1                | 160mm      | 160mm    | No         |
| 34562-762      | 3U          | 1                | 220mm      | 220mm    | No         |

ADDITIONAL PRODUCT DETAILS

Для последующего монтажа разделительной панели в уже смонтированный блочный каркас требуется предварительно демонтировать горизонтальные рейки.

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)



Our powerful portfolio of brands:

CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE