


# EuropacPRO Guide Rails to Accomodate Conduction Cooled Assemblies

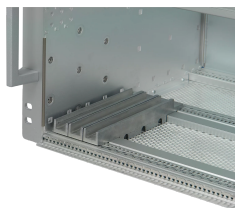

Адаптер представляет собой интерфейс между блочным каркасом и модулями с кондуктивным охлаждением (CCA).

## CERTIFICATIONS



## FEATURES

Адаптер для крепления модулей с кондуктивным охлаждением (CCA) в блочных каркасах

## SPECIFICATIONS

|                        |                                                                |
|------------------------|----------------------------------------------------------------|
| <b>Material:</b>       | Алюминий                                                       |
| <b>Works With:</b>     | Блочный каркас; Coffrets                                       |
| <b>Product Family:</b> | EuropacPRO; RatiopacPRO; RatiopacPRO AIR; CompacPRO; PropacPRO |
| <b>Product Type:</b>   | Направляющие рельсы                                            |

Table 1/2

| Catalog Number | Type                           | Package Quantity | Groove Width | Finish     | Длина мм | Package Unit |
|----------------|--------------------------------|------------------|--------------|------------|----------|--------------|
| 24566-004      | Conduction Cooled Assembly VPX | 2                | 13.3         | Passivated | 160mm    | Pair         |

| CatalogNumber | Type                                  | Package Quantity | Groove Width | Finish     | Длина мм | Package Unit |
|---------------|---------------------------------------|------------------|--------------|------------|----------|--------------|
| 24566-005     | Conduction Cooled Assembly CompactPCI | 2                | 13.3         | Passivated | 160mm    | Pair         |

| Table 2/2      |            |
|----------------|------------|
| Catalog Number | Quick Ship |
| 24566-004      | No         |
| 24566-005      | No         |

ADDITIONAL PRODUCT DETAILS

Подходит для усиленных и упрочненных горизонтальных реек.

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)



Our powerful portfolio of brands:

CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE