


Монтажная панель EuropacPRO для использования с защитной крышкой

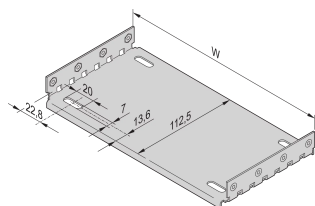

Монтажная панель для использования с заглушками для установки и крепления тяжелых компонентов. Монтажные панели полной ширины (как и блочный каркас или системный корпус) крепятся к боковым стенкам. Монтажные панели частичной ширины крепятся к боковой панели и горизонтальной рейке с помощью монтажной рейки.

Направляющие типа 4,4-дюймовые и усиленные не могут использоваться в сочетании с монтажной панелью. Верхняя/нижняя крышка, которая будет вставлена в паз легких горизонтальных реек (тип L), не может использоваться в сочетании с монтажной панелью.

CERTIFICATIONS



FEATURES

Для установки и крепления тяжелых компонентов

Монтажная плата, полная ширина: Монтажная панель имеет такую же ширину, как и блочный каркас, и крепится к боковым стенкам

Возможен монтаж направляющих в первый и последний слот

Помимо монтажной панели на блочном каркасе могут быть также установлены ЭМС-крышки

Нельзя использовать направляющие типа 4,4 и «усиленные» направляющие

Возможен монтаж направляющих в первый и последний слот

SPECIFICATIONS

Material:	Алюминий
Product Family:	EuropacPRO
Product Type:	Монтажная панель
Works With:	Блочный каркас

Table 1/1

Catalog Number	Rack Width	Package Quantity	Глубина мм	Ширина мм	Certifications	Quick Ship
34563-004	84HP	1	112.5mm	431.35mm	RoHS	No
34563-019	63HP	1	172.5mm	324.67mm	RoHS	No
34563-014	42HP	1	172.5mm	217.99mm	RoHS	No
34563-009	28HP	1	172.5mm	146.88mm	RoHS	No
34563-003	63HP	1	112.5mm	324.67mm	RoHS	No
34563-002	42HP	1	112.5mm	217.99mm	RoHS	No
34563-001	28HP	1	112.5mm	146.88mm	RoHS	No
34563-024	84HP	1	172.5mm	431.35mm	RoHS	No
34563-044	84HP	1	412.5mm	431.35mm		No
34563-042	84HP	1	352.5mm	431.35mm		No
34563-028	84HP	1	292.5mm	431.35mm		No
34563-026	84HP	1	232.5mm	431.35mm		No

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE