


Front Panel EMC Textile Shielding Kit, -40 up to +70°C

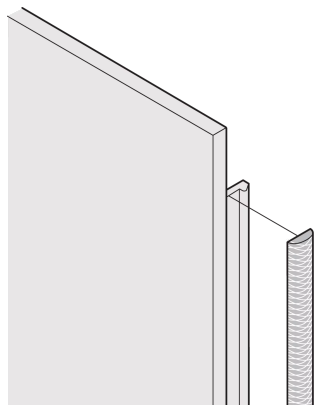

Текстильные ЭМС-прокладки вставляются в слот с правой стороны U-образных передних панелей. Прокладки приклеиваются к передней панели.

CERTIFICATIONS



FEATURES

Текстильный ЭМС-уплотнитель крепится сбоку на передней панели или при необходимости в пазу правого профиля.

Профильное уплотнение наклеивается на контактную поверхность 19-дюймового кронштейна или заднего угла и устанавливает токопроводящее соединение с U-образными передними панелями.

Диапазон температур -40 °C.. +70 °C

SPECIFICATIONS

Works With:	Блочный каркас; Coffrets; Передние панели
Product Family:	EuropacPRO; RatiopacPRO; RatiopacPRO AIR; PropacPRO; Frame Type Plug-In Unit
Product Type:	Shielding Kit
Material:	Thermoplastic Elastomer

Table 1/2

Catalog Number	Rack Height	Package Quantity	Глубина мм (D)	Высота мм (H)	Ширина мм (W)	Flammability Rating
21101-978	5U	10				
21101-857	2U	10	1.62mm	52mm	3.8mm	UL® 94V-0
21101-853	3U	10	1.62mm	97mm	3.8mm	UL® 94V-0
21101-858	4U	10				
21101-854	3U	100	1.62mm	97mm	3.8mm	UL® 94V-0
21101-855	6U	10	1.62mm	232mm	3.8mm	UL® 94V-0
21101-856	6U	100	1.62mm	232mm	3.8mm	UL® 94V-0
21101-904	9U	100				
21101-859	9U	10	1.62mm	365.5mm	3.8mm	UL® 94V-0

Table 2/2


Catalog Number	Quick Ship
21101-978	No
21101-857	No
21101-853	No
21101-858	No
21101-854	No
21101-855	No
21101-856	No

Catalog Number	Quick Ship
21101-904	No
21101-859	No

ADDITIONAL PRODUCT DETAILS

ЭМС-прокладки (текстильные) необходимы для экранирования передних панелей.

DIAGRAMS

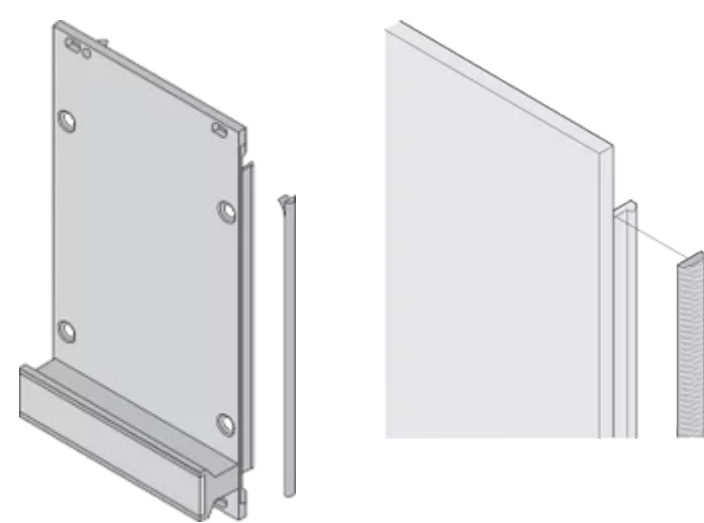

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE