


**передняя панель, плоская, возможно
дооснащение экранированием, Вырезы D-
Sub**

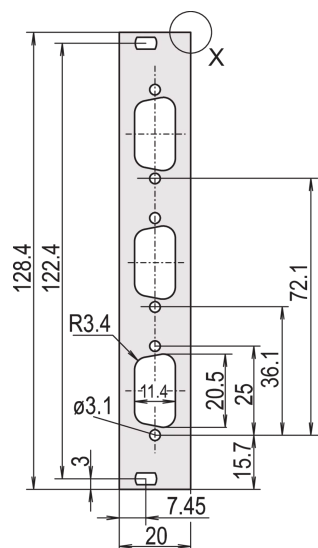

Плоская передняя панель с вырезом для разъемов D-Sub. Возможность экранирования ЭМС-прокладкой из нержавеющей стали.

CERTIFICATIONS



FEATURES

Для ЭМС-прокладки из нержавеющей стали

алюминий, 2,5 мм, лицевая поверхность анодированная, токопроводящая

SPECIFICATIONS

Rack Height:	3U
Rack Width:	4HP
Material:	Алюминий
Finish:	Anodized; Passivated
Аксессуар Тип:	Передняя панель

Product Type: Передняя панель
Type: Front Panel without Handle
EMC Shielding: No (Retrofittable)

Table 1/2

Catalog Number	Package Quantity	Mounting	EMC Gasket Type	Front Finish	Rear Finish	Number of Pins
30118-348	1	Screw-on Front	Нержавеющая сталь	Anodized	Conductive	(1) 9
30118-349	1	Screw-on Front	Нержавеющая сталь	Anodized	Conductive	(1) 15
30118-350	1	Screw-on Front	Нержавеющая сталь	Anodized	Conductive	(1) 25
30118-351	1	Screw-on Front	Нержавеющая сталь	Anodized	Conductive	(2) 9
30118-352	1	Screw-on Front	Нержавеющая сталь	Anodized	Conductive	(2) 15
30118-353	1	Screw-on Front	Нержавеющая сталь	Anodized	Conductive	(2) 25
30118-354	1	Screw-on Front	Нержавеющая сталь	Anodized	Conductive	(3) 9

Table 2/2

Catalog Number	Treated Edges	Complies With	Глубина мм (D)	Высота мм (H)	Ширина мм (W)	Quick Ship
30118-348	Нет	IEC 60297-3-101, IEEE 1101.1/10	2.5mm	128.4mm	19.98mm	No
30118-349	Нет	IEC 60297-3-101, IEEE 1101.1/10	2.5mm	128.4mm	19.98mm	No
30118-350	Нет	IEC 60297-3-101, IEEE 1101.1/10	2.5mm	128.4mm	19.98mm	No
30118-351	Нет	IEC 60297-3-101, IEEE 1101.1/10	2.5mm	128.4mm	19.98mm	No
30118-352	Нет	IEC 60297-3-101, IEEE 1101.1/10	2.5mm	128.4mm	19.98mm	No
30118-353	Нет	IEC 60297-3-101, IEEE 1101.1/10	2.5mm	128.4mm	19.98mm	No

CatalogNumber	Treated Edges	Complies With	Глубина мм(D)	Высота мм (H)	Ширина мм(W)	Quick Ship
30118-354	Нет	IEC 60297-3-101, IEEE 1101.1/10	2.5mm	128.4mm	19.98mm	No

ADDITIONAL PRODUCT DETAILS


Крепежный материал (втулки, винты с проточкой) заказывается отдельно.





Поставка исключительно в размере товарной партии. Цена указана за отдельную единицу.

ЭМС-прокладка из нержавеющей стали заказывается отдельно.

Обратите внимание, что поставки доступны в указанных стандартных товарных партиях (товарная партия, например, 5 шт., 10 шт., 50 шт. и т. д.). Другие объемы заказов (например, 2 шт.) могут округляться вверх до следующего возможного размера стандартной товарной партии.

DIAGRAMS

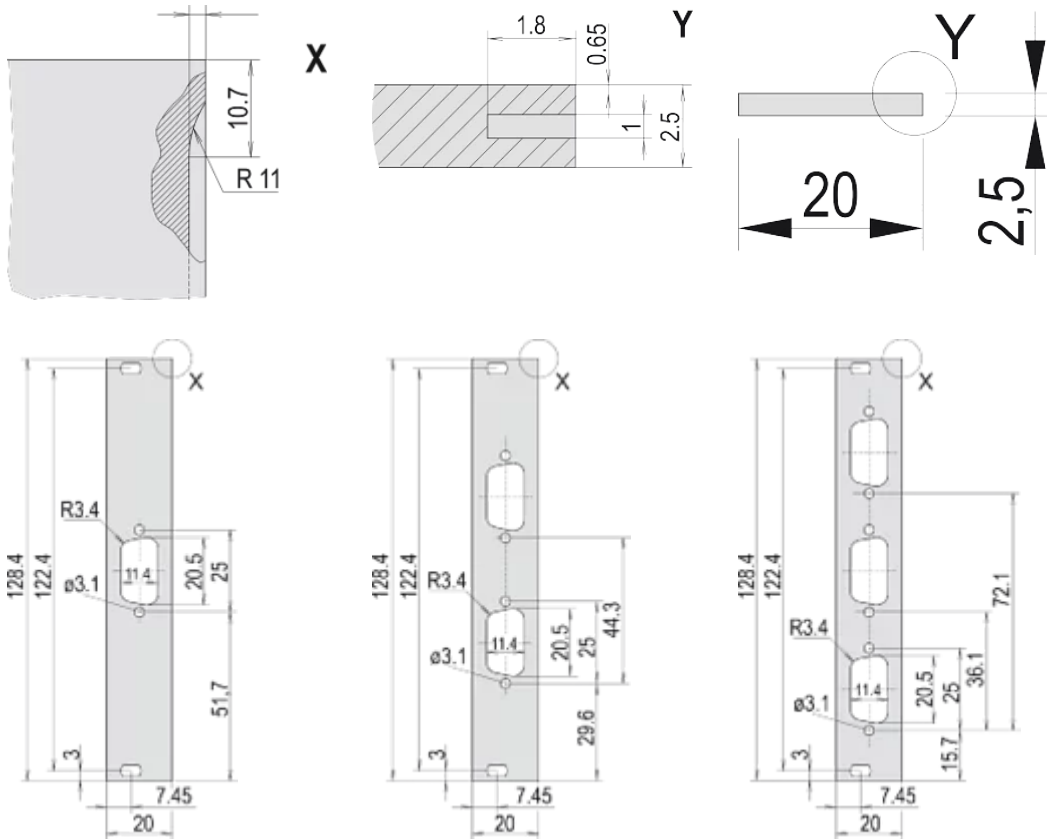

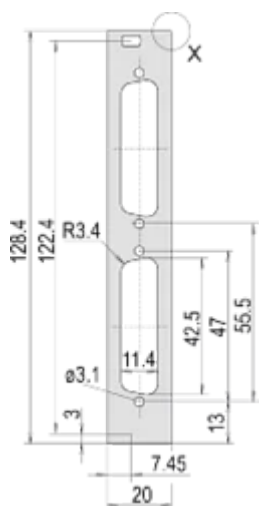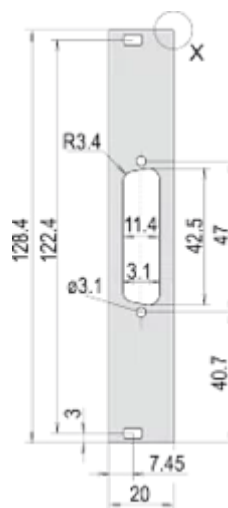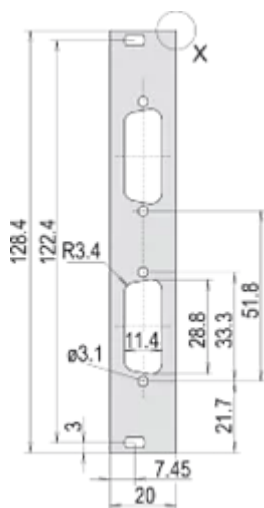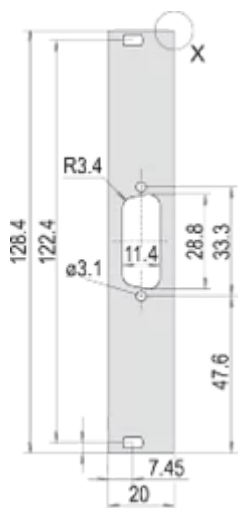

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void any warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:

nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE