


передняя панель, плоская, Без экранирования, Вырезы D-Sub

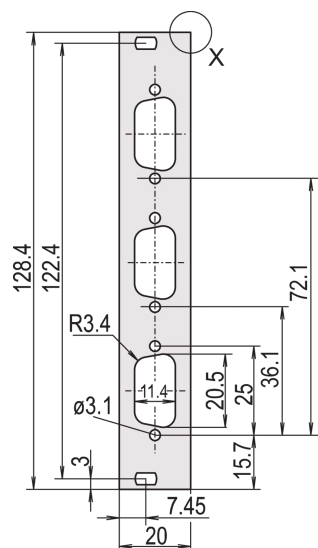

Плоская передняя панель с вырезом для разъемов D-Sub. Неэкранированный вариант исполнения.

CERTIFICATIONS



FEATURES

Вариант исполнения без экранирования

алюминий, 2,5 мм, лицевая поверхность анодированная, тыльная поверхность электропроводящая

SPECIFICATIONS

Rack Height:	3U
Rack Width:	4HP
Material:	Алюминий
Finish:	Anodized; Passivated
Аксессуар Тип:	Передняя панель
Product Type:	Передняя панель

Type: Front Panel without Handle

Table 1/2

Catalog Number	Package Quantity	Mounting	Front Finish	Rear Finish	Number of Pins	Treated Edges
30118-341	1	Screw-on Front	Anodized	Conductive	(3) 9	Нет
30118-342	1	Screw-on Front	Anodized	Conductive	(1) 15	Нет
30118-343	1	Screw-on Front	Anodized	Conductive	(1) 25	Нет
30118-344	1	Screw-on Front	Anodized	Conductive	(2) 9	Нет
30118-345	1	Screw-on Front	Anodized	Conductive	(2) 15	Нет
30118-346	1	Screw-on Front	Anodized	Conductive	(2) 25	Нет
30118-347	1	Screw-on Front	Anodized	Conductive	(3) 9	Нет

Table 2/2

Catalog Number	Complies With	Глубина мм (D)	EMC Shielding	Высота мм (H)	Ширина мм (W)	Quick Ship
30118-341	IEC 60297-3-101, IEEE 1101.1/10	2.5mm	Нет	128.4mm	19.98mm	No
30118-342	IEC 60297-3-101, IEEE 1101.1/10	2.5mm	Нет	128.4mm	19.98mm	No
30118-343	IEC 60297-3-101, IEEE 1101.1/10	2.5mm	Нет	128.4mm	19.98mm	No
30118-344	IEC 60297-3-101, IEEE 1101.1/10	2.5mm	Нет	128.4mm	19.98mm	No
30118-345	IEC 60297-3-101, IEEE 1101.1/10	2.5mm	Нет	128.4mm	19.98mm	No
30118-346	IEC 60297-3-101, IEEE 1101.1/10	2.5mm	Нет	128.4mm	19.98mm	No

CatalogNumber	Complies With	Глубина мм(D)	EMC Shielding	Высота мм (H)	Ширина мм(W)	Quick Ship
30118-347	IEC 60297-3-101, IEEE 1101.1/10	2.5mm	Нет	128.4mm	19.98mm	No


ADDITIONAL PRODUCT DETAILS



Поставка исключительно в размере товарной партии. Цена указана за отдельную единицу.

Крепежный материал (втулки, винты с проточкой) заказывается отдельно.

Обратите внимание, что поставки доступны в указанных стандартных товарных партиях (товарная партия, например, 5 шт., 10 шт., 50 шт. и т. д.). Другие объемы заказов (например, 2 шт.) могут округляться вверх до следующего возможного размера стандартной товарной партии.

DIAGRAMS

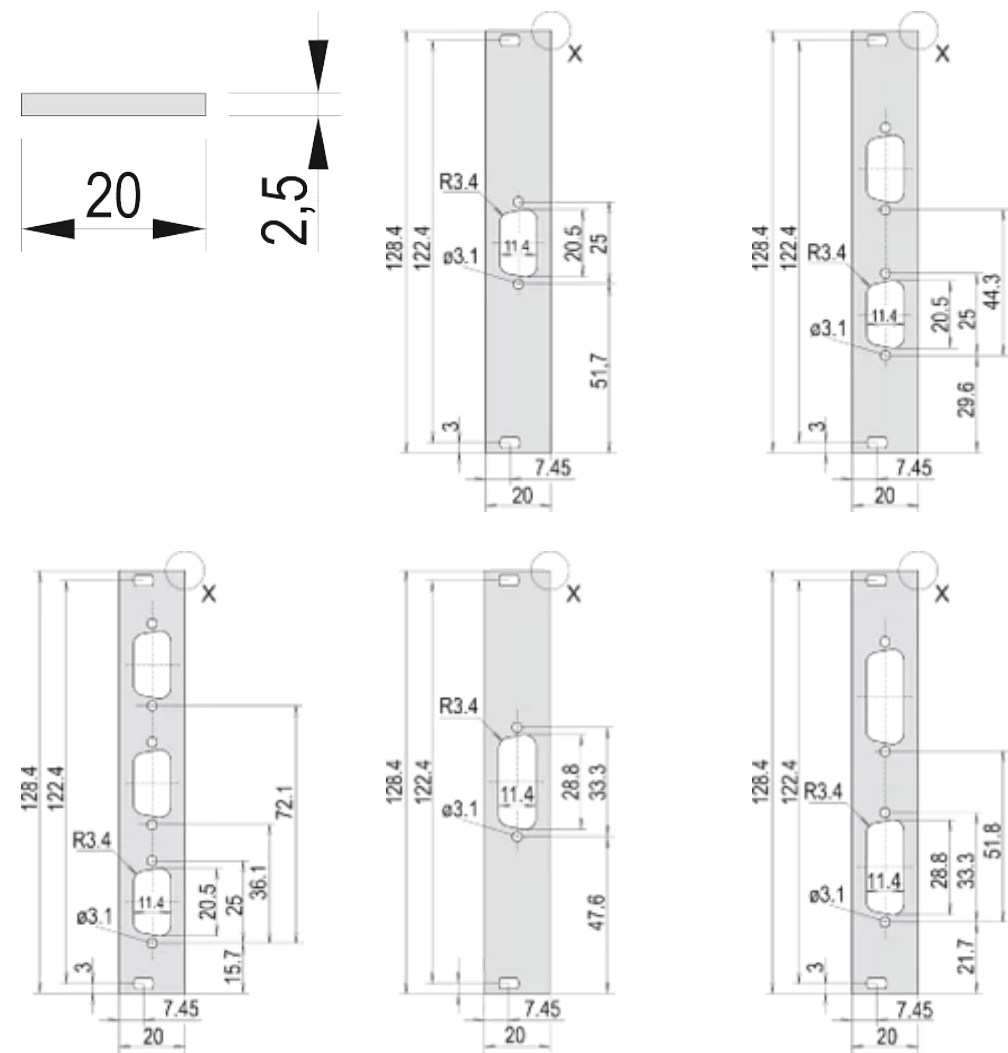

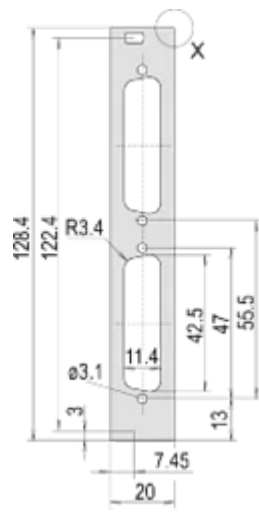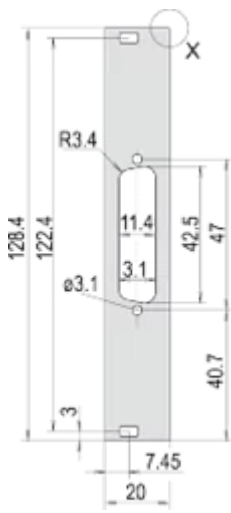

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE