


Держатель вентилятора Interscale с вентиляторами

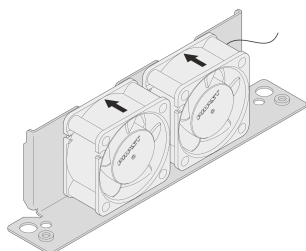

Держатель вентилятора Interscale с вентиляторами, для настольных корпусов и 19-дюймовых шасси. Доступны в различных размерах и с тремя вариантами вентиляторов с расходом воздуха от 10 до 170 м3/ч.

FEATURES

Держатель вентилятора для установки на дне корпуса

Вентиляторы легко крепятся к держателю вентилятора с помощью демпфирующего вибрацию крепежного материала

Крепление держателей вентилятора фиксируется в настольном корпусе с помощью 2 пластиковых ножек или в 19-дюймовом корпусе с помощью 2 винтов.

Держатель вентилятора нельзя использовать вместе с монтажной пластиной (вместо этого используйте монтажную панель со встроенным держателем вентилятора)

Для технических данных вентиляторов, посмотрите, что входит в поставку

SPECIFICATIONS

Finish: Aluminum-Zinc Plated

Type: Fan Tray

Product Type: Fan Unit

Input Voltage DC: 12V min

Table 1/2

Catalog Number	Ширина мм	Глубина мм	Package Quantity	Max Static Pressure	Max Ambient Temperature	Airflow
24828-104	40mm	20mm	1		70°C	10m³/h
24828-105	40mm	20mm	1		70°C	10m³/h

CatalogNumber	Ширина мм	Глубина мм	Package Quantity	Max Static Pressure	Max Ambient Temperature	Airflow
24828-107	40mm	20mm	1		70°C	10m³/h
24828-204	80mm	25mm	1		70°C	19m³/h
24828-205	80mm	25mm	1		70°C	19m³/h
24828-207	80mm	25mm	1		70°C	19m³/h
24828-305	119mm	25mm	1		70°C	170m³/h
24828-307	119mm	25mm	1		70°C	170m³/h
24830-101	80mm	25mm	1	95.41Pa	70°C	109m³/h
24830-102	80mm	25mm	1			

Table 2/2

Catalog Number	Noise Level	Высота мм	Material	Мощность W	Product Family	Quick Ship
24828-104	18dB(A)	40mm	Сталь	0.9W	Interscale	No
24828-105	18dB(A)	40mm	Сталь	0.9W	Interscale	No
24828-107	18dB(A)	40mm	Сталь	0.9W	Interscale	No
24828-204	32dB(A)	80mm	Сталь	2W	Interscale	No
24828-205	32dB(A)	80mm	Сталь	2W	Interscale	No
24828-207	32dB(A)	80mm	Сталь	2W	Interscale	No
24828-305	43dB(A)	119mm	Сталь	5.3W	Interscale	No
24828-307	43dB(A)	119mm	Сталь	5.3W	Interscale	No

CatalogNumber	Noise Level	Высота мм	Material	Мощность W	Product Family	Quick Ship
24830-101	44.62dB(A)	80mm	Сталь			No
24830-102		80mm	Сталь			No

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE