


Винт с полукруглой головкой, Torx, Самозажимной

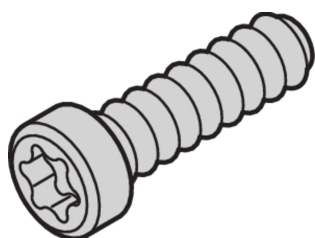

Винты со сферо-цилиндрической головкой Torx с различной метрической резьбой и различной длины. С дополнительными функциями, такими как заземление или самоконтрящаяся резьба.

CERTIFICATIONS



FEATURES

Винт со сферо-цилиндрической головкой с Torx, самостопорящийся

SPECIFICATIONS

Type:	Panhead Screw
Product Type:	Screw
Material:	Сталь

Table 1/1

Catalog Number	Длина мм	Finish	Package Quantity	Thread Size	Works With	Quick Ship
24560-159	6mm	Zinc Plated	100	M2.5	Backplanes, Test Adapters	No
21500-039	9.3mm	Zinc Plated	100	M2.5	Передние панели, Horizontal Rails, Type H, Horizontal Rails, Type R	No

ADDITIONAL PRODUCT DETAILS

Макс. момент затяжки 0,2 Нм

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE