

Комплект вставного модуля с трапецевидной ручкой, Без экранирования, серый



Вставной модуль со статичной ручкой и плоской передней панелью. Серая ручка собрана на передней панели.

CERTIFICATIONS



FEATURES

Плоская передняя панель

Ручка без функции извлечения

SPECIFICATIONS

Material:	Алюминий
Finish:	Anodized; Passivated
Product Type:	Передняя панель
Type:	Front Panel with Handle (PIU)

Table 1/3

Catalog Number	Rack Height	Rack Width	Package Quantity	Handle Type	Mounting	Front Finish
----------------	-------------	------------	------------------	-------------	----------	--------------

20818-017	3U	3HP	1	Трапецевидн ой ручкой, антистатическ	Screw-on Front	Anodized
20818-018	3U	4HP	1	Трапецевидн ой ручкой, антистатическ	Screw-on Front	Anodized
20818-019	3U	5HP	1	Трапецевидн ой ручкой, антистатическ	Screw-on Front	Anodized
20818-020	3U	6HP	1	Трапецевидн ой ручкой, антистатическ	Screw-on Front	Anodized
20818-021	3U	7HP	1	Трапецевидн ой ручкой, антистатическ	Screw-on Front	Anodized
20818-022	3U	8HP	1	Трапецевидн ой ручкой, антистатическ	Screw-on Front	Anodized
20818-023	3U	10HP	1	Трапецевидн ой ручкой, антистатическ	Screw-on Front	Anodized
20818-024	3U	12HP	1	Трапецевидн ой ручкой, антистатическ	Screw-on Front	Anodized
20818-025	6U	4HP	1	Трапецевидн ой ручкой, антистатическ	Screw-on Front	Anodized
20818-026	6U	5HP	1	Трапецевидн ой ручкой, антистатическ	Screw-on Front	Anodized
20818-027	6U	6HP	1	Трапецевидн ой ручкой, антистатическ	Screw-on Front	Anodized
20818-028	6U	8HP	1	Трапецевидн ой ручкой, антистатическ	Screw-on Front	Anodized
20818-029	6U	10HP	1	Трапецевидн ой ручкой, антистатическ	Screw-on Front	Anodized
20818-120	6U	12HP	1	Трапецевидн ой ручкой, антистатическ	Screw-on Front	Anodized
20818-162	6U	7HP	1	Трапецевидн ой ручкой, антистатическ	Screw-on Front	Anodized

Table 2/3

Catalog Number	Rear Finish	Treated Edges	Flammability Rating	Complies With	EMC Shielding	Высота мм (H)
20818-017	Passivated	Нет	UL® 94V-0	EN 45545-2, R22-R24, HL3, IEC 60297-3-101	Нет	128.4mm
20818-018	Passivated	Нет	UL® 94V-0	EN 45545-2, R22-R24, HL3, IEC 60297-3-101	Нет	128.4mm
20818-019	Passivated	Нет	UL® 94V-0	EN 45545-2, R22-R24, HL3, IEC 60297-3-101	Нет	128.4mm
20818-020	Passivated	Нет	UL® 94V-0	EN 45545-2, R22-R24, HL3, IEC 60297-3-101	Нет	128.4mm
20818-021	Passivated	Нет	UL® 94V-0	EN 45545-2, R22-R24, HL3, IEC 60297-3-101	Нет	128.4mm
20818-022	Passivated	Нет	UL® 94V-0	EN 45545-2, R22-R24, HL3, IEC 60297-3-101	Нет	128.4mm
20818-023	Passivated	Нет	UL® 94V-0	EN 45545-2, R22-R24, HL3, IEC 60297-3-101	Нет	128.4mm
20818-024	Passivated	Нет	UL® 94V-0	EN 45545-2, R22-R24, HL3, IEC 60297-3-101	Нет	128.4mm
20818-025	Passivated	Нет	UL® 94V-0	EN 45545-2, R22-R24, HL3, IEC 60297-3-101	Нет	261.8mm
20818-026	Passivated	Нет	UL® 94V-0	EN 45545-2, R22-R24, HL3, IEC 60297-3-101	Нет	261.8mm
20818-027	Passivated	Нет	UL® 94V-0	EN 45545-2, R22-R24, HL3, IEC 60297-3-101	Нет	261.8mm


CatalogNumber	Rear Finish	Treated Edges	Flammability Rating	Complies With	EMC Shielding	Высота мм (H)
20818-028	Passivated	Нет	UL® 94V-0	EN 45545-2, R22-R24, HL3, IEC 60297-3-101	Нет	261.8mm
20818-029	Passivated	Нет	UL® 94V-0	EN 45545-2, R22-R24, HL3, IEC 60297-3-101	Нет	261.8mm
20818-120	Passivated	Нет	UL® 94V-0	EN 45545-2, R22-R24, HL3, IEC 60297-3-101	Нет	261.8mm
20818-162	Passivated	Нет	UL® 94V-0	EN 45545-2, R22-R24, HL3, IEC 60297-3-101	Нет	261.8mm

Table 3/3

Catalog Number	Ширина мм (W)	Quick Ship
20818-017	14.9mm	No
20818-018	20mm	No
20818-019	25mm	No
20818-020	30.1mm	No
20818-021	35.2mm	No
20818-022	40.3mm	No
20818-023	50.5mm	No
20818-024	60.6mm	No
20818-025	20mm	No
20818-026	25mm	No

Catalog Number	Ширина мм (W)	Quick Ship
20818-027	30.1mm	No
20818-028	40.3mm	No
20818-029	50.5mm	No
20818-120	60.6mm	No
20818-162	35.2mm	No

DIAGRAMS

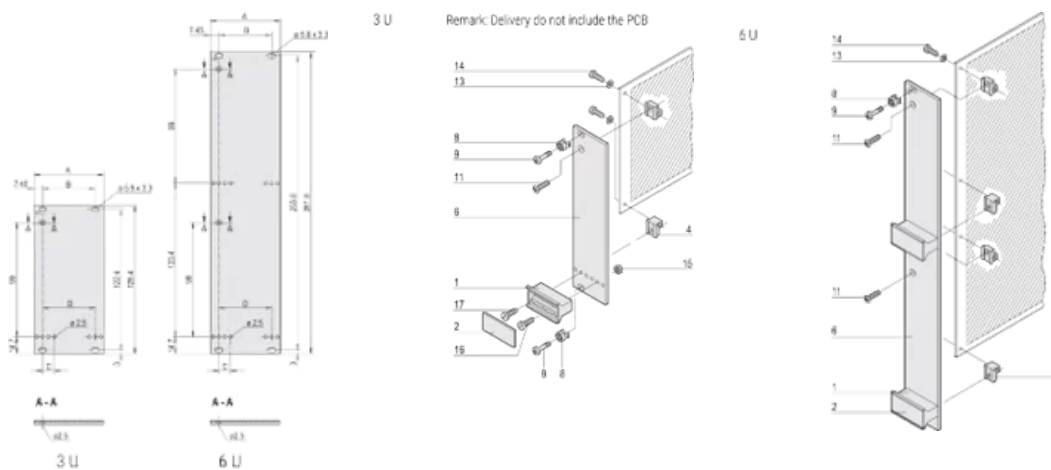

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE