


Задняя панель PropacPRO, полная ширина, Без экранирования

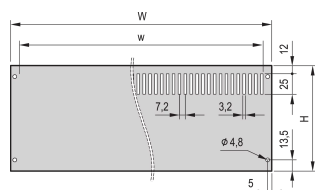

Задняя панель по всей ширине корпуса PropacPRO крепится к раме корпуса. С вентиляционными слотами или без них.

CERTIFICATIONS



FEATURES

Алюминиевая панель, толщина материала 2,0 мм (для ширины 84 HP 2,5 мм)

Монтаж с опорным кронштейном на корпусе (справа и слева)

SPECIFICATIONS

Material:	Алюминий
Finish:	Anodized
Works With:	Coffrets
Product Family:	PropacPRO
Type:	Rear Panel
Product Type:	Side Panel

Table 1/1

Catalog Number	Rack Height	Rack Width	Design Feature	Package Quantity	Quick Ship
24576-044	2U	42HP	Без перфорации	1	No
24576-144	2U	42HP	С перфорацией	1	No

Catalog Number	Rack Height	Rack Width	Design Feature	Package Quantity	Quick Ship
24576-045	2U	63HP	Без перфорации	1	No
24576-145	2U	63HP	С перфорацией	1	No
24576-047	3U	28HP	Без перфорации	1	No
24576-147	3U	28HP	С перфорацией	1	No
24576-048	3U	42HP	Без перфорации	1	No
24576-148	3U	42HP	С перфорацией	1	No
24576-049	3U	63HP	Без перфорации	1	No
24576-149	3U	63HP	С перфорацией	1	No
24576-050	3U	84HP	Без перфорации	1	No
24576-150	3U	84HP	С перфорацией	1	No
24576-052	4U	42HP	Без перфорации	1	No
24576-152	4U	42HP	С перфорацией	1	No
24576-053	4U	63HP	Без перфорации	1	No
24576-153	4U	63HP	С перфорацией	1	No
24576-054	4U	84HP	Без перфорации	1	No
24576-154	4U	84HP	С перфорацией	1	No
24576-058	6U	84HP	Без перфорации	1	No
24576-158	6U	84HP	С перфорацией	1	No

Catalog Number	Rack Height	Rack Width	Design Feature	Package Quantity	Quick Ship
24576-046	2U	84HP	Без перфорации	1	No
24576-146	2U	84HP	С перфорацией	1	No

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE